


DATASHEET

RG174 SMB Connector Socket, straight

Version 03/17

Item no. : 1493138

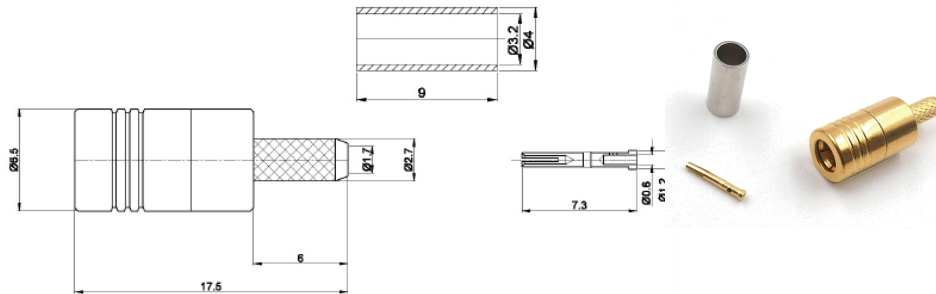

Tolerance ± 0.1

Impedance	50Ω
Insulation resistance	500 MΩ
Connection	Crimp
Cable O.D.	2.59 mm
Frequency	Max. 4 GHz
Material.....	Brass, Gold Plated
Operation Temperature/ Humidity	-20°C to 70°C, 10% - 90%
Storage Temperature/ Humidity	-20°C to 70°C, 10% - 90%

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).
All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represent the technical status at the time of printing.

© Copyright 2016 by Conrad Electronic SE.