


Wall-mount Remote Control – 6 buttons

Product ref.: 142308A0

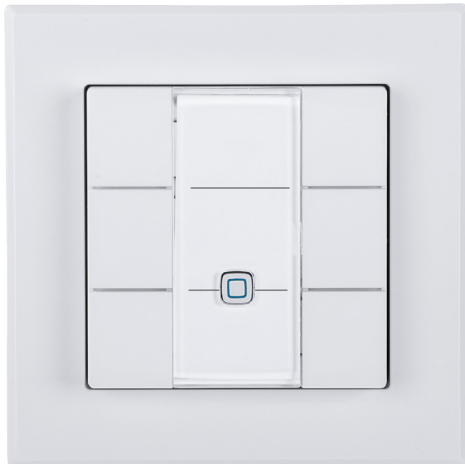

Product features

- Wall-mount remote control for universal use with six buttons for comfortable control of connected devices - buttons can be configured as pairs or individually
- Can be used e.g. for switching lights on and off or for activating and deactivating alarm functions
- Individual labelling of buttons with replaceable labelling field
- Simple and flexible installation thanks to supplied adhesive strips or screws
- Easy to integrate into existing switches from the following manufacturers: Berker (S.1, B.1, B.3, B.7 Glas), GIRA (System 55, Standard 55, E2, E22, Event, Esprit), Merten (1-M, Atelier-M, M-Smart, M-Arc, M-Star, M-Plan), JUNG (A 500, AS 500, A plus, A creation), Busch Jäger (Duro 2000® SI/ SI Linear, Reflex SI/I Linear, carat®, future® linear, solo®, Busch® axcent, alpha, balance® SI and ELSO (Joy)
- Can be used with the Access Point in connection with the Homematic IP app, the Homematic Central Control Unit CCU2 as well as with various partner solutions

Technical specifications

Supply voltage	2x 1.5 V LR03/micro/AAA
Current consumption	50 mA max.
Battery life	4 years (typ.)
Degree of protection	IP20
Ambient temperature	5 to 35 °C
Dimensions (W x H x D)	Without frame: 55 x 55 x 20 mm Incl. frame: 86 x 86 x 22 mm
Weight	95 g (including batteries)
Radio frequency	868.3 MHz/869.525 MHz
Typ. open area RF range	200 m

Logistical data

Product reference	142308A0
EAN code	4047976423088
Short description	HmIP-WRC6
Packing unit	90
Packing dimensions	122 x 112 x 48 mm

Package contents

Homematic IP Wall-mount Remote Control - 6 buttons

Clip-on frame

Mounting plate

Double-sided adhesive strips (2x)

Screws 3.0 x 30 mm (2x) and plugs 5 mm (2x)

1.5 V LR03/micro/AAA batteries (2x)

Operating manual