


Model No.: **GP15A**

NO MERCURY ADDED	
Description	: Mercury & Cadmium Free Alkaline Manganese Battery, AA Size
Chemical System	: Alkaline Manganese
Nominal Voltage	: 1.5 Volts
Nominal Dimensions	: Ø14.5 mm x 50.5 mm
Terminals	: Protruded positive(+) and flat negative(-) contacts
Jacket	: Foil jacket
Applications	: All electronic devices, e.g. toys, photographic equipment, data banks, calculators, audio appliances, remote controls, paging machines.
Warranty Period	: 36 months
Average Weight	: 24g


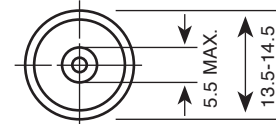


Cross References:

GP	JIS	IEC	Eveready	Duracell
15A	LR6	LR6	E91	MN1500

Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
10 Ohms	24 Hrs/ Day	0.9V	19 Hrs

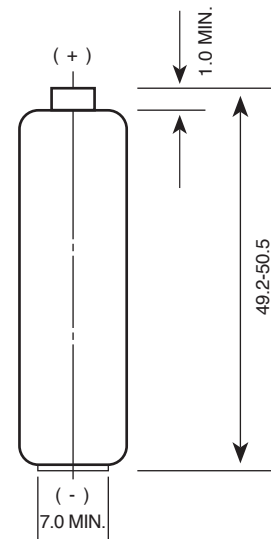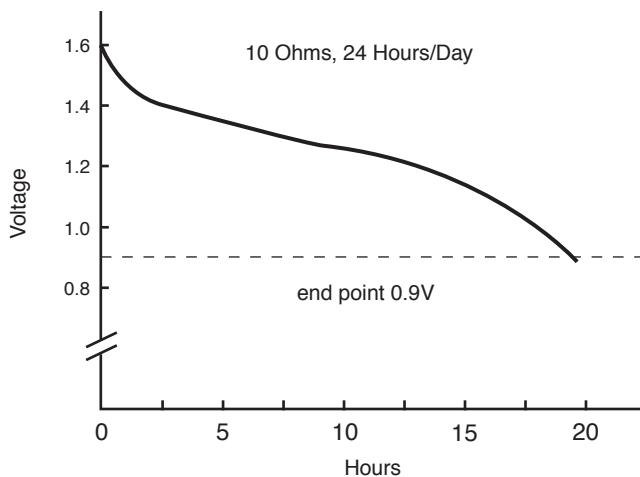


Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.

Model No.: **GP24A**

NO MERCURY ADDED	
Description	: Mercury Free Alkaline Manganese Battery, AAA Size
Chemical System	: Alkaline Manganese
Nominal Voltage	: 1.5 Volts
Nominal Dimensions	: Ø10.5 mm x 44.5 mm
Terminals	: Protruded positive(+) and flat negative(-) contacts
Jacket	: Foil jacket
Applications	: All electronic devices, e.g. toys, photographic equipment, data banks, calculators, audio appliances, remote controls, paging machines.
Warranty Period	: 36 months
Average Weight	: 11.4g


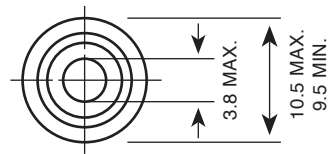


Cross References:

GP	JIS	IEC	Eveready	Duracell	Varta
24A	LR03	LR03	E92	MN2400	4003

Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
20 Ohms	24 Hrs/ Day	0.9V	17.2 Hrs

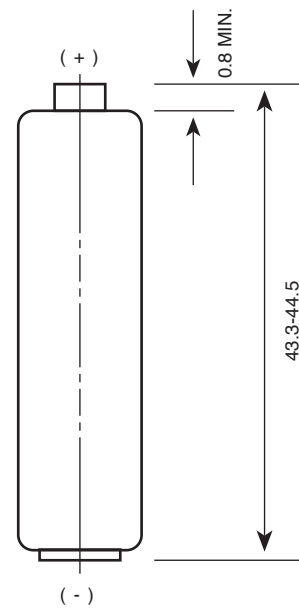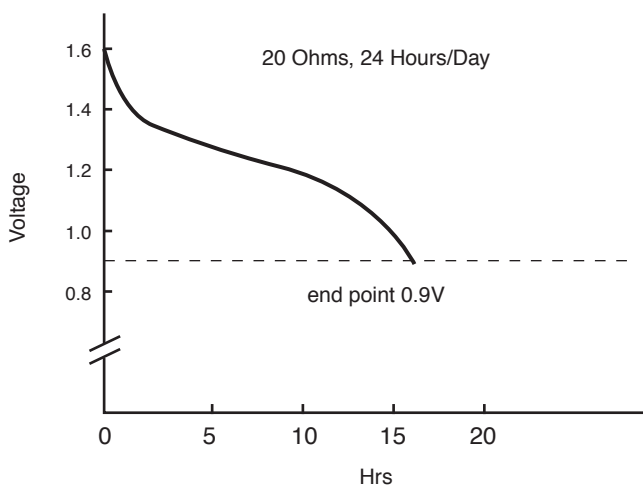

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.