

# LogiLink®

## Power Cord

German Plug to IEC C13 female 90°

Art. No.: CP117  
CP118  
CP119



### Features:


- » Connection 1: German plug (CEE 7/7), straight
- » Connection 2: IEC-C13 female (IEC 60320-C13), 90° angled
- » H05VV-F
- » VDE tested, 10A, 250V
- » Color: Black



Art-No.	Cable	Length	EAN Code
CP117	Ø 3 x 0.75mm <sup>2</sup>	2m	4052792038903
CP118	Ø 3 x 1.0mm <sup>2</sup>	3m	4052792038910
CP119	Ø 3 x 1.5mm <sup>2</sup>	5m	4052792038927

### Technical Drawing:

CP117

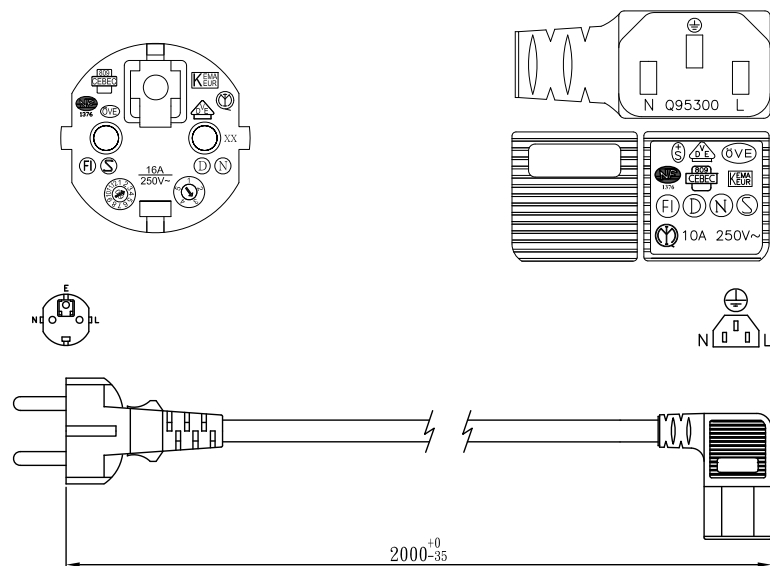

RoHS  
compliant



\* The specifications and pictures are subject to change without notice.

\*All trade names referenced are the registered trademark of their respective owners.

Made in China

Best Connectivity

# LogiLink®



## Power Cord

German Plug to IEC C13 female 90°

Art. No.: CP117  
CP118  
CP119

### Package Contents:

» 1 x Power Cord

### Packaging Information:

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
CP117	288 x 118mm	0.19kg	546 x 355 x 197mm	90pc	18.9kg
CP118	288 x 118mm	0.29kg	546 x 355 x 197mm	60pc	18.67kg
CP119	348 x 140mm	0.65kg	546 x 355 x 197mm	30pc	20.13kg

Best Connectivity



RoHS  
compliant



\* The specifications and pictures are subject to change without notice.

\* All trade names referenced are the registered trademark of their respective owners.

Made in China