


A32



Dimensions

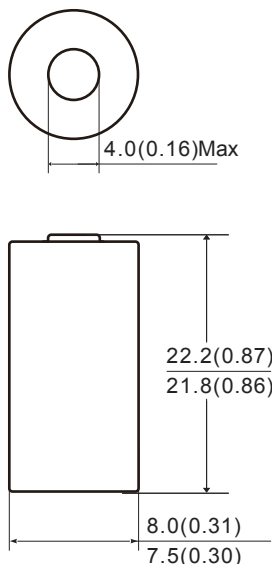

Unit:mm(inch)

ZERO MERCURY

Alkaline Button Stack

Specifications

Chemical System:	Alkaline(Zn/MnO ₂) (Zinc-Manganese Dioxide)
Camelion Model:	A32
Average Weight:	3.8g
Dimension(ΦxH)	7.7 x 21.8mm 0.30x 0.86 inch
Terminals:	Flat
Nominal Voltage:	9Volts
Capacity:	24mAh (Rated at 20kohm to 4.8V)
Operating Temperature:	-18°C -55°C
Storage Temperature:	15°C -25°C
Relative Humidity:	60±15%

Usage Guide



Remote control




Doorbell



Lighter

Typical Discharge Testing Typical characteristics at 21 °C

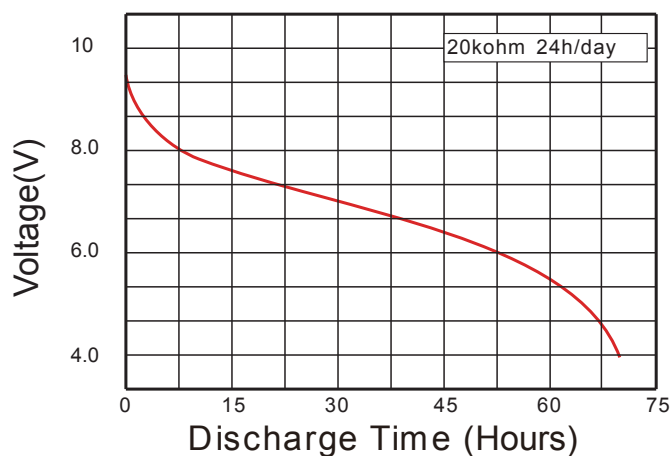

Notice:

Environmental elements comply with 2006/66/EC and US LAW 104-142 requirements. This data sheet is typical information specific to products manufactured at the time of its publication. Contact Camelion Battery Co., Ltd. for the latest information.