


## AG9

## ZERO MERCURY

## Alkaline Button Cell



### Dimensions

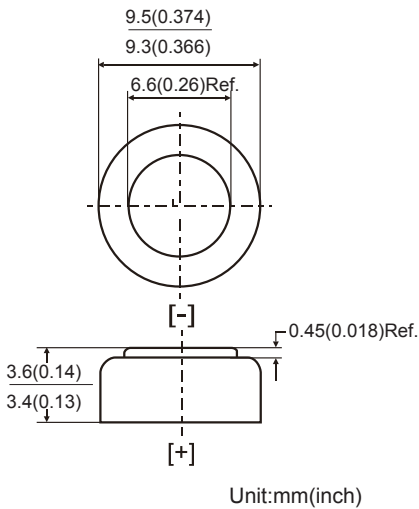

### Specifications

Chemical System:	Alkaline (Zn/MnO <sub>2</sub> ) (Zinc-Manganese Dioxide)
IEC Name:	LR45
Camelion Model:	AG9 (LR936)
Average Weight:	0.88g
Dimension (Φ x H):	9.4 x 3.5mm 0.37 x 0.14 inch
Terminals:	Flat
Nominal Voltage:	1.5 Volts
Capacity:	60mAh (Rated at 15kohm to 0.9V)
Operating Temperature:	-18°C - 55°C
Storage Temperature:	15°C - 25°C
Relative Humidity:	60 ± 15%

### Usage Guide



Watch




Calliper



Calculator

### Typical Discharge Testing

Typical characteristics at 21 °C

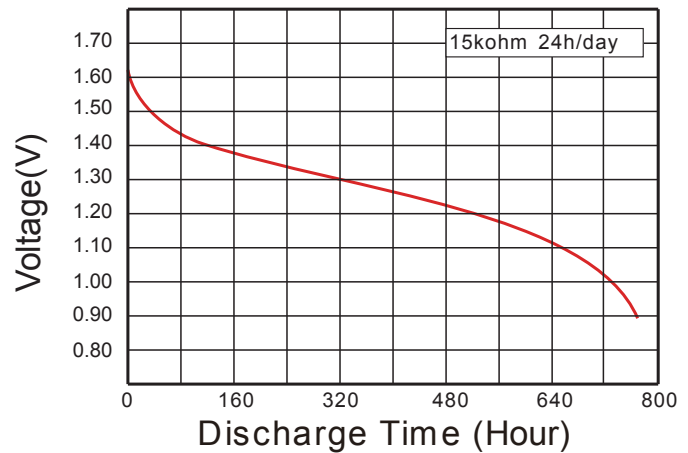

**Notice:**

Environmental elements comply with 2006/66/EC and US LAW 104-142 requirements. This data sheet is typical information specific to products manufactured at the time of its publication. Contact Camelion Battery Co., Ltd. for the latest information.