



TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	UL Recognised Plastic Material
Plating:	Nickel over Copper
Operating Temperature:	-55°C to +110°C
Cable Entry:	Side / Top / Side
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 13mm

D-Sub High Density:

Insulator:	PBT, Black, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute
Insulator resistance:	500MΩ min

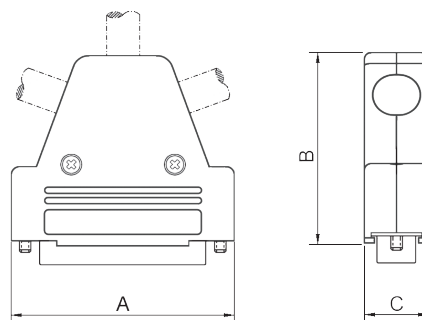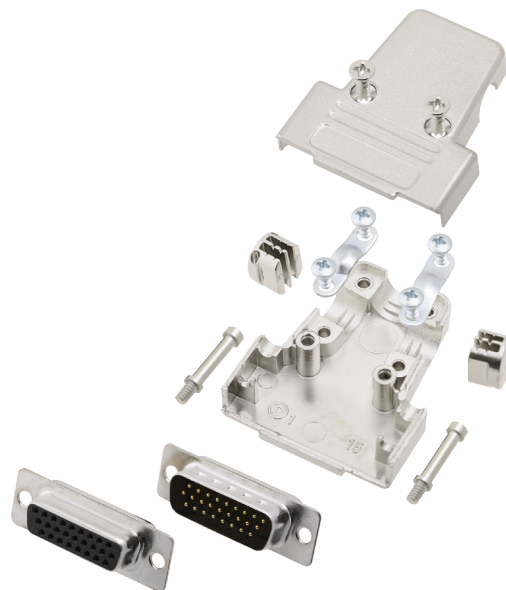

D-Sub-Hood

Features:

- Available in sizes 9-15-25-37
- All sizes feature 3-Way Entry solution
- Re-openable
- Hood is supplied with 2 Blanking Plates and 2 Strain Relief clamps.

Size TRI-M	Dim A	Dim B	Dim C
9-way	31,0	45,2	15,0
15-way	40,3	45,2	15,0
25-way	53,5	45,2	15,0
37-way	70,0	45,2	15,0

Ordering information:**D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
HD 15	6355-0058-01	TRI-M-09-HDP15-K
HD 26	6355-0058-02	TRI-M-15-HDP26-K
HD 44	6355-0058-03	TRI-M-25-HDP44-K
HD 62	6355-0058-04	TRI-M-37-HDP62-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
HD 15	6355-0058-11	TRI-M-09-HDS15-K
HD 26	6355-0058-12	TRI-M-15-HDS26-K
HD 44	6355-0058-13	TRI-M-25-HDS44-K
HD 62	6355-0058-14	TRI-M-37-HDS62-K