

TECHNICAL SPECIFICATIONS

D-Sub Hood:



Material:	UL 94 V-0 Plastic Material
Plating:	Nickel over Copper
Operating Temperature:	-55°C to +110°C
Cable Entry:	Side Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm

Female D-Sub Solder Cup:

Insulator:	PBT, Black, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed Pins	Class 3, 100 inserts min.
Machined Contact Pins:	Class 1, 500 inserts min.
Contact Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	1000V for 1 minute
Insulator resistance:	1000MΩ min.

Features:

- Available in sizes 9-15-25-37
- Suitable for any common Sub-D Connector
- Strain relief inserts ensure a secure termination
- Re-openable
- Recyclable

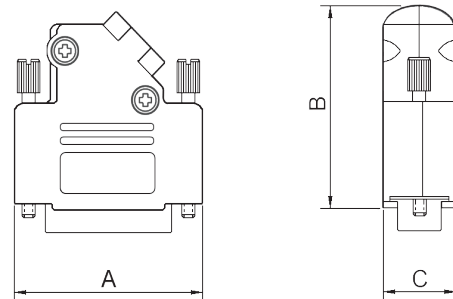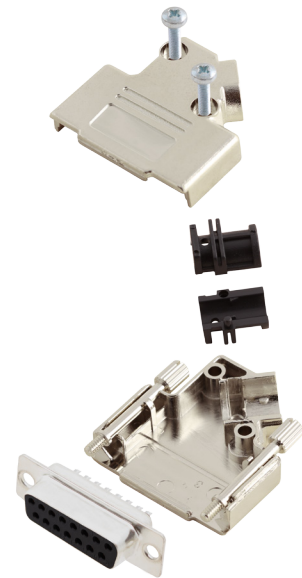

D-Sub-Hood

Grommet Sizes D45PK-M:



Size D45PK-M	Dim A	Dim B	Dim C
9-way	31,0	36,3	15,0
15-way	39,5	40,3	15,0
25-way	53,2	40,3	15,0
37-way	69,7	40,3	15,0

Ordering information:**Class 3 D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-0009-11	D45PK-M-09-DBS-K
15-way	6355-0009-12	D45PK-M-15-DBS-K
25-way	6355-0009-13	D45PK-M-25-DBS-K
37-way	6355-0009-14	D45PK-M-37-DBS-K

Ordering information:**Class 1 D-SubConnector Kits (500 inserts min.)**

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-0010-11	D45PK-M-09-DMS-K
15-way	6355-0010-12	D45PK-M-15-DMS-K
25-way	6355-0010-13	D45PK-M-25-DMS-K
37-way	6355-0010-14	D45PK-M-37-DMS-K