

TECHNICAL SPECIFICATIONS

D-Sub Hood:


Material: UL 94 V-0 Plastic Material
 Operating Temperature: -55°C to +110°C
 Cable Entry: Side
 Thumbscrews: UNC 4-40 (Standard)
 Cable O.D.: Up to 11,5mm
 Colour: Black

Male Sub-D Connector:


Insulator: PBT, Black, UL94 V-0
 Shell: Steel, Tin Plated
 Contact pins: Copper Alloy
 Stamped & Formed Pins: Class 3, 100 inserts min.
 Machined Contact Pins: Class 1, 500 inserts min.
 Contact Plating: Selective Gold over Nickel
 Operating Temperature: -55°C to +105°C
 Withstanding voltage: 1000V for 1 minute
 Insulator resistance: 1000MΩ min.

Features:

- Available in sizes 9-15-25-37
- Suitable for any common Sub-D connector
- Strain relief inserts ensure a secure termination
- Re-openable

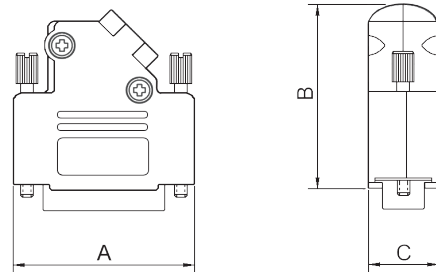

D-Sub-Hood

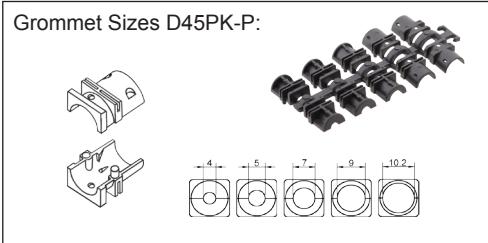

Size D45PK-P	Dim A	Dim B	Dim C
9-way	31,0	36,3	15,0
15-way	39,5	40,3	15,0
25-way	53,2	40,3	15,0
37-way	69,7	40,3	15,0

Ordering information:

Class 3 D-Sub Connector Kits (100 inserts min.)

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-0034-01	D45PK-P-09-DBP-K
15-way	6355-0034-02	D45PK-P-15-DBP-K
25-way	6355-0034-03	D45PK-P-25-DBP-K
37-way	6355-0034-04	D45PK-P-37-DBP-K

Ordering information:

Class 1 D-Sub Connector Kits (500 inserts min.)

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-0035-01	D45PK-P-09-DMP-K
15-way	6355-0035-02	D45PK-P-15-DMP-K
25-way	6355-0035-03	D45PK-P-25-DMP-K
37-way	6355-0035-04	D45PK-P-37-DMP-K