

**Industrial Ethernet
IE-FCI-PWB-AU-10A****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 1429-0

Fax: +49 5231 14292083

www.weidmueller.com



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-FCI-PWB-AU-10A
Order No.	1546590000
Version	FrontCom, Insert Power large, Socket, AU, 10 A
GTIN (EAN)	4050118351842
Qty.	1 pc(s).

**Industrial Ethernet
IE-FCI-PWB-AU-10A**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Technical data
Dimensions and weights

Net weight	36.2 g
------------	--------

Temperatures

Operating temperature	-5 °C...50 °C	Storage temperature	-10 °C...70 °C
Installation temperature			

Technical data

Housing main material	Polycarbonate PC	Rated current	10 A
Rated voltage (AC)	240 V		

General data

Insert type	Insert Power large	Protection degree	IP20
-------------	--------------------	-------------------	------

Clampable conductors

Conductor connection cross-section, extremely flexible with wire end ferrule	1.5 ... 2.5 mm ²	Conductor connection cross-section, extremely flexible without wire end ferrule	1.5 ... 4 mm ²
Conductor connection cross-section, flexible with wire end ferrule	1.5 ... 2.5 mm ²	Conductor connection cross-section, flexible without wire end ferrule	1.5 ... 4 mm ²
Conductor connection cross-section, rigid	1.5 ... 4 mm ²	Stripping length	9 mm
Type of connection	Screw connection		

Standards

Certificate No. (GERMLLOYD)	13866-15
-----------------------------	----------

Classifications

ETIM 5.0	EC000456	ETIM 6.0	EC001121
UNSPSC	31-16-23-03	eClass 6.2	27-26-12-90
eClass 7.1	27-18-92-17	eClass 8.1	27-18-92-17
eClass 9.0	27-18-92-17		

Approvals

Approvals




ROHS	Conform
------	---------

Industrial Ethernet IE-FCI-PWB-AU-10A

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Drawings

Dimensioned drawing

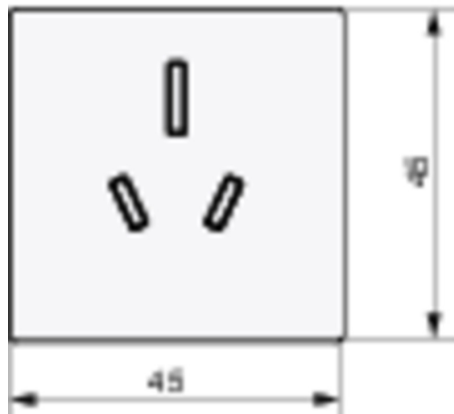

Dimensioned drawing

