


Φ22 mm, USB3.0 FEMALE A - MALE A with 150cm Cable
Item no.: 1515256 - Silver
1515255- Black

Version 11/16

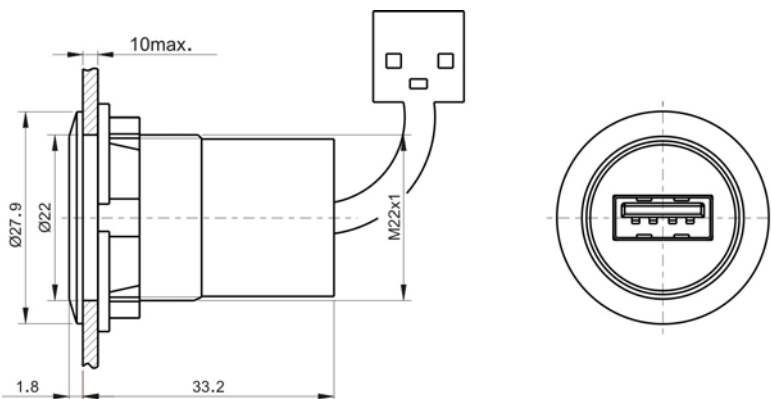

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification	USB3.0 FEMALE A –MALE A with 150cm cable
Mounting diameter	22 mm
Body material	aluminium anodized
Operating and storage temperature	-20 to +55 °C
Operating and storage humidity	45 to 85 % RH
Panel thickness	1 ~ 10 mm
Transmission speed	≥100MB/s

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represent the technical status at the time of printing.

© Copyright 2016 by Conrad Electronic SE.