


Toolless BNC terminal adaptor, Male

Version 01/17

Item no. 1523970

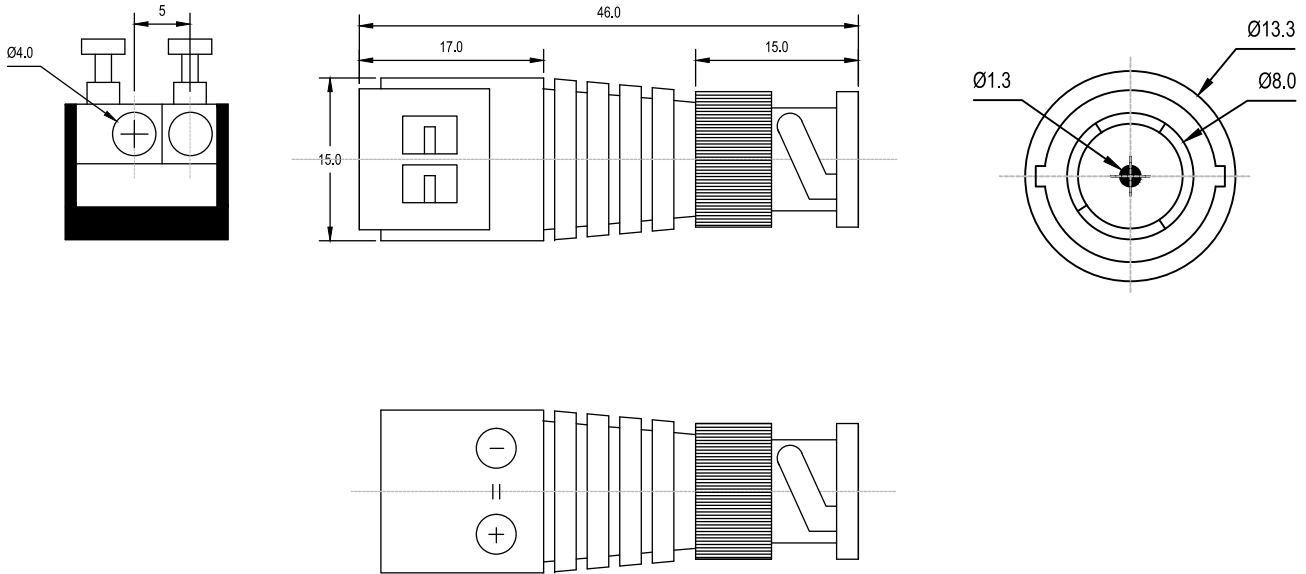

Technical Data:

Electrical:

Frequency Range	DC-1GHz
Normal Impedance	50Ω
Voltage rating.....	12VDC
Current rating.....	2A
Contact resistance	Centre 1.5mΩ/Outer 0.2mΩ
Dielectric withstanding voltage	1500V
Wire range	22-16 AWG

Mechanical:

Torque.....	0.4 Nm (3.5lb/in)
Operating temperature.....	-40°C to 105°C
Strip length.....	6mm

Distributed by Conrad Electronic SE

This data sheet is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This data represent the technical status at the time of printing. Changes in technology and equipment reserved.

© Copyright 2017 by Conrad Electronic SE.