


Neon Signal lamp, Red

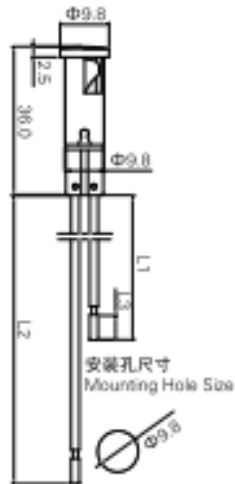

Voltage.....	230V, 50 / 60 Hz
Current.....	2 mA
Light.....	Neon
Mounting hole.....	Ø 9.5 mm
Mounting panel thickness.....	0.8 - 3 mm
H05S-K wire heat resistance.....	180 °C
Life time.....	25000 h
Color.....	Red
Terminal.....	Connection: open end
Material of lamp base.....	PC
Material of lamp holder.....	Nylon / PBT
Operating& Storage temperature.....	0 to 100 °C ; Storage -20 to 120 °C
Operating& Storage humidity.....	10 - 80 % RH