


Neon Signal lamp, Green

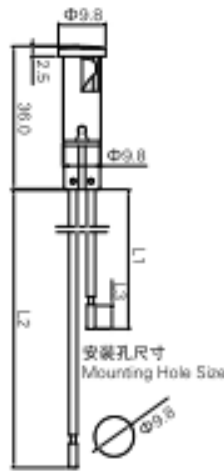

| | |
|-------------------------------------|-------------------------------------|
| Voltage..... | 230V, 50 / 60 Hz |
| Current..... | 2 mA |
| Light..... | Neon |
| Mounting hole..... | Ø 9.5 mm |
| Mounting panel thickness..... | 0.8 - 3 mm |
| H05S-K wire heat resistance..... | 180°C |
| Life time..... | Less than 25000 h |
| Color..... | Green |
| Terminal..... | Connection: open end |
| Material of lamp base..... | PC |
| Material of lamp holder..... | Nylon / PBT |
| Operating& Storage temperature..... | 0 to 100 °C ; Storage -20 to 120 °C |
| Operating& Storage humidity..... | 10 - 80 % RH |