


Data Sheet

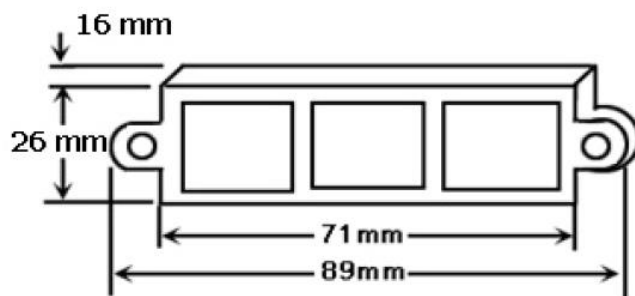

Voltage: 24 V/DC

Current: 4.2 – 6.2 A

Power (max.): 100 W – 150 W

Surface temperature (max.): 100 - 130°C (210 - 260°F)

Plastic frame (PPS) temperature (max.): 300°C