

HSK-standard cable glands

HSK-M / HSK-M-PVDF


Metr.



Material	Nickel plated brass
Clamping insert	Polyamide / PVDF
Seal	Buna-N / FPM
O-Ring	Buna-N / FPM
Protection	IP 68 – 10 bar / IP 69K (NEMA 6 – 150 PSIG) within the specified clamping range
Operating Temperature	-40 °C – 100 °C (-40 °F – 212 °F) (PA) -35 °C – 150 °C (-31 °F – 302 °F) (PVDF)



Advice:
 - Other sealing material e.g. Silicone upon request
 - Please see page 51 for size < M12 and > M63

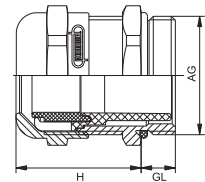

AG	\varnothing mm	GL mm	H mm	\varnothing mm	Number HSK-M -40 °C – 100 °C -40 °F – 212 °F	Number HSK-M-PVDF -35 °C – 150 °C -31 °F – 302 °F
M 12 x 1,5	3 – 6,5	6,5	19	14	1.609.1200.50	1.699.1200.50
M 12 x 1,5	2 – 5	6,5	19	14	1.609.1200.51	1.699.1200.51
M 16 x 1,5	4 – 8	6	21	17 / 19	1.609.1600.50	1.699.1600.50
M 16 x 1,5	2 – 6	6	21	17 / 19	1.609.1600.51	1.699.1600.51
M 16 x 1,5	5 – 10	6	22	20	1.609.1611.50	1.699.1611.50
M 20 x 1,5	6 – 12	6	23	22	1.609.2000.50	1.699.2000.50
M 20 x 1,5	5 – 9	6	23	22	1.609.2000.51	1.699.2000.51
M 20 x 1,5	10 – 14	6	24	24	1.609.2016.50	1.699.2016.50
M 25 x 1,5	13 – 18	7	26	30	1.609.2500.50	1.699.2500.50
M 25 x 1,5	9 – 16	7	26	30	1.609.2500.51	1.699.2500.51
M 32 x 1,5	18 – 25	8	31	40	1.609.3200.50	1.699.3200.50
M 32 x 1,5	13 – 20	8	31	40	1.609.3200.51	1.699.3200.51
M 32 x 1,5	15 – 21	8	33	36	1.609.3200.52	
M 40 x 1,5	22 – 32	8	37	50	1.609.4000.50	1.699.4000.50
M 40 x 1,5	20 – 26	8	37	50	1.609.4000.51	1.699.4000.51
M 40 x 1,5	19 – 27	8	33	46	1.609.4000.52	
M 50 x 1,5	32 – 38	9	37	57	1.609.5000.50	
M 50 x 1,5	25 – 31	9	37	57	1.609.5000.51	
M 63 x 1,5	37 – 44	10	38	64 / 68	1.609.6300.50	
M 63 x 1,5	29 – 35	10	38	64 / 68	1.609.6300.51	

➔ Accessories see page 73