


Coaxial PCB Connector 82_MMBX-S50-0-13/111_N

Description

Straight PCB jack

Interface Standards
SUHNER-MMBX

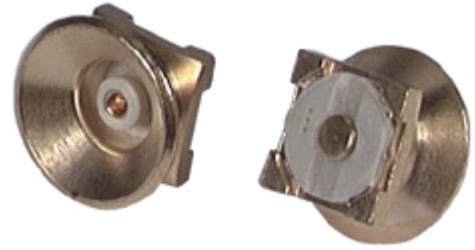

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	12.4 GHz

Mechanical Data

Board mounting type	surface mount
Weight	0.0008 kg

Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	SUCOPRO Plating
Outer contact	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	LCP (Liquid crystal polymer)	

Related Documents

Outline drawing	DOU-00001894
Catalogue drawing	DCA-00087583
Mounting hole	DOU-00012611

Ordering Information

Bulk 100 pcs package	82_MMBX-S50-0-13/111_NH
Tape and Reel package	82_MMBX-S50-0-13/111_NM
Single package	82_MMBX-S50-0-13/111_NE

Remarks

PCB connector with stand-offs