


Sucotest Assemblies

Description

ID (Product Code) 84004594
 Description (Product) ST18/SMAM/Nm/36in

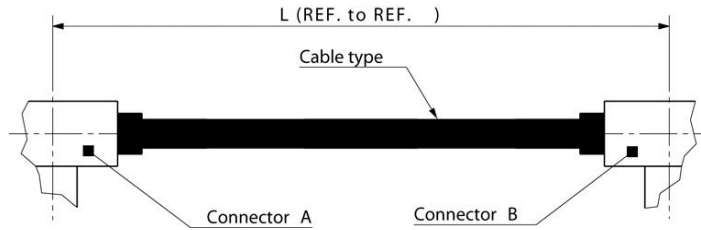

Product Configuration

Cable SUCOTEST_18
 Connector A SF_11_SMA-373
 Connector B SF_11_N-372

Technical Data

Electrical Data

Impedance 50 Ω
 Operating Frequency 6 to 18 GHz
 Min. Return Loss \geq 25 dB
 Max. Attenuation 1.51 dB
 Signal Delay 4.3 ns \pm ns

Mechanical Data

Weight 90 kg
 Length REF/REF 914 mm \pm mm
 Max. Tensile Force 200 N

Environmental Data

Operating Temperature -55 °C to + 105 °C
 2011/65/EU (RoHS) compliant
 2002/96/EC, WEEE no special marking needed