


Coaxial Cable Connector 16_TNC-50-7-4/133_N

Description

Right angle cable plug

Interface standards

IEC 60169-17_MIL-STD-348A/313_CECC 22200

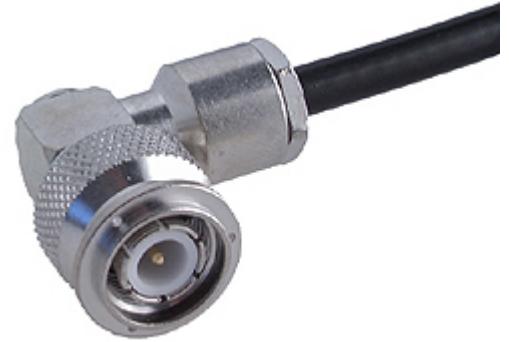

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	11 GHz

Mechanical Data

Centre contact	soldered
Outer contact	clamped
Weight	0.0561 kg

Environmental Data

Operating temperature 2011/65/EC, RoHS	-65 °C to 165 °C compliant
---	-------------------------------

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Brass	SUCOPLATE (R) Plating
Body	Brass	SUCOPLATE (R) Plating
Insulator	PFA / PTFE	
Coupling nut	Brass	SUCOPLATE (R) Plating
Gasket	VMQ (Silicone rubber)	

Related Documents

Outline drawing	DOU-00006367
Catalogue drawing	DOU-00006369
Assembly instruction	DOC-0000179896

Ordering Information

Single package	16_TNC-50-7-4/133_NE
----------------	----------------------

Additional Information

Suitable cables	RG_213_/U, RG_214_/U, RG_393_/U, ENVIROFLEX_393
-----------------	---