


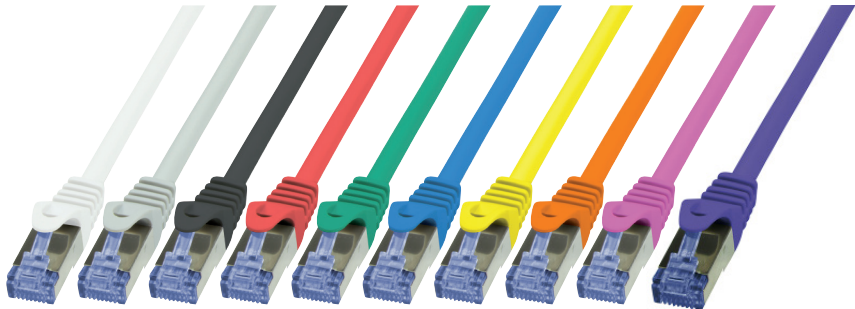

Cat.6A 10G S/FTP Patch Cable PrimeLine

Technical Features

Cat.6A ClassEA S/FTP RJ45 Patch Cord

Compliant to ISO/IEC 11801 & EN 50173


AWG26/7 copper wire

Shielded RJ45 plugs with gold plated pins

Shielded twisted pair cable, pairs in metal foil (PIMF) LSZH (low smoke zero halogen)

6.2 mm ±0.2 mm outer dimension

Technical Drawings

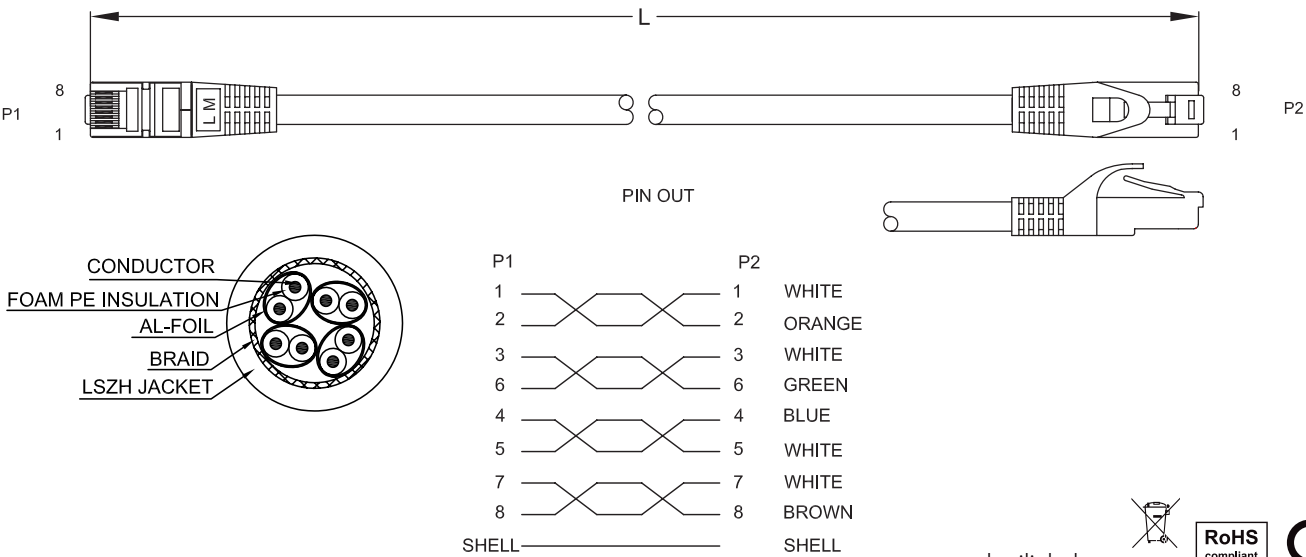


Length	White	EAN Code
0.25 m	CQ3011S	4052792020045
0.50 m	CQ3021S	4052792020052
1.00 m	CQ3031S	4052792020069
1.50 m	CQ3041S	4052792020076
2.00 m	CQ3051S	4052792020083
3.00 m	CQ3061S	4052792020090
5.00 m	CQ3071S	4052792020106
7.50 m	CQ3081S	4052792020113
10.00 m	CQ3091S	4052792020120
15.00 m	CQ3101S	4052792020137
20.00 m	CQ3111S	4052792020144
30.00 m	CQ3121S	4052792020151
50.00 m	CQ3141S	4052792020168



Length	Grey	EAN Code	Black	EAN Code
0.25 m	CQ3012S	4052792020175	CQ3013S	4052792020267
0.50 m	CQ3022S	4052792020182	CQ3023S	4052792020274
1.00 m	CQ3032S	4052792020199	CQ3033S	4052792020281
1.50 m	CQ3042S	4052792020205	CQ3043S	4052792020298
2.00 m	CQ3052S	4052792020212	CQ3053S	4052792020304
3.00 m	CQ3062S	4052792020229	CQ3063S	4052792020311
5.00 m	CQ3072S	4052792020236	CQ3073S	4052792020328
7.50 m	CQ3082S	4052792020243	CQ3083S	4052792020335
10.00 m	CQ3092S	4052792020250	CQ3093S	4052792020342
15.00 m	CQ3102S	4052792029369	CQ3103S	4052792040579
20.00 m	CQ3112S	4052792029376	CQ3113S	4052792040586
30.00 m	CQ3122S	4052792029383	CQ3123S	4052792040593
50.00 m	CQ3142S	4052792029390	CQ3143S	4052792040609

Length	Red	EAN Code
0.25 m	CQ3014S	4052792020359
0.50 m	CQ3024S	4052792020366
1.00 m	CQ3034S	4052792020373
1.50 m	CQ3044S	4052792020380
2.00 m	CQ3054S	4052792020397
3.00 m	CQ3064S	4052792020403
5.00 m	CQ3074S	4052792020410
7.50 m	CQ3084S	4052792020427
10.00 m	CQ3094S	4052792020434

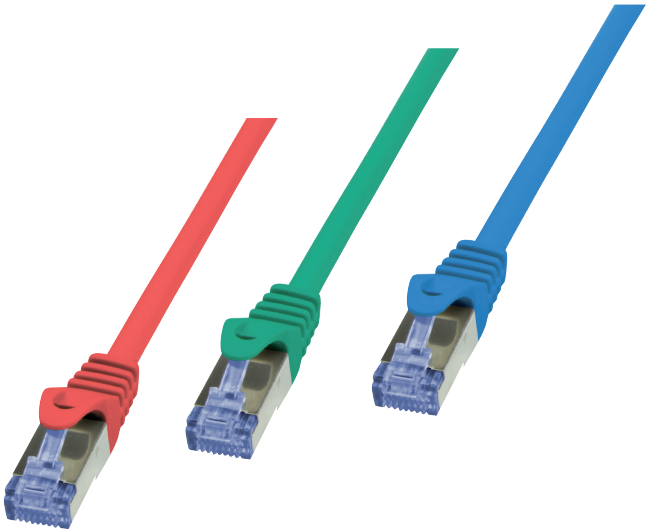

Length	Green	EAN Code	Blue	EAN Code
0.25 m	CQ3015S	4052792020441	CQ3016S	4052792020533
0.50 m	CQ3025S	4052792020458	CQ3026S	4052792020540
1.00 m	CQ3035S	4052792020465	CQ3036S	4052792020557
1.50 m	CQ3045S	4052792020472	CQ3046S	4052792020564
2.00 m	CQ3055S	4052792020489	CQ3056S	4052792020571
3.00 m	CQ3065S	4052792020496	CQ3066S	4052792020588
5.00 m	CQ3075S	4052792020502	CQ3076S	4052792020595
7.50 m	CQ3085S	4052792020519	CQ3086S	4052792020601
10.00 m	CQ3095S	4052792020526	CQ3096S	4052792020618



Length	Yellow	EAN Code	Violet	EAN Code
0.25 m	CQ3017S	4052792020625	CQ301VS	4052792043235
0.50 m	CQ3027S	4052792020632	CQ302VS	4052792043242
1.00 m	CQ3037S	4052792020649	CQ303VS	4052792043259
1.50 m	CQ3047S	4052792020656	CQ304VS	4052792043266
2.00 m	CQ3057S	4052792020663	CQ305VS	4052792043273
3.00 m	CQ3067S	4052792020670	CQ306VS	4052792043280
5.00 m	CQ3077S	4052792020687	CQ307VS	4052792043297
7.50 m	CQ3087S	4052792020694	CQ308VS	4052792043303
10.00 m	CQ3097S	4052792020700	CQ309VS	4052792043310

Length	Orange	EAN Code	Pink	EAN Code
0.25 m	CQ3018S	4052792020717	CQ3019S	4052792020809
0.50 m	CQ3028S	4052792020724	CQ3029S	4052792020816
1.00 m	CQ3038S	4052792020731	CQ3039S	4052792020823
1.50 m	CQ3048S	4052792020748	CQ3049S	4052792020830
2.00 m	CQ3058S	4052792020755	CQ3059S	4052792020847
3.00 m	CQ3068S	4052792020762	CQ3069S	4052792020854
5.00 m	CQ3078S	4052792020779	CQ3079S	4052792020861
7.50 m	CQ3088S	4052792020786	CQ3089S	4052792020878
10.00 m	CQ3098S	4052792020793	CQ3099S	4052792020885

Package Contents

Cat.6A S/FTP Patch Cable x 1

Packaging Informations (CQ3xx1S white/CQ3xx2S grey)

Packing Dimension	120 x 160mm (0.25-0.5m)/140 x 180mm (1-1.5m)/160 x 200mm (2-3m)/180 x 230mm (5-7.5m)/200 x 240mm (10-15m)/220 x 260mm (20-30m)/300 x 330mm (50m)
Packing Weight	0.02kg (0.25m)/0.03kg (0.5m)/0.05kg (1m)/0.06kg (1.5m)/0.08kg (2m)/0.11kg (3m)/0.18kg (5m)/0.28kg (7.5m)/0.35kg (10m)/0.52kg (15m)/0.68kg (20m)/1.05kg (30m)/1.75kg (50m)
Carton Dimension	360 x 360 x 300mm (7.5m)/400 x 300 x 200mm (20m)/400 x 300 x 220mm (0.25m,15m)/400 x 300 x 230mm (30m)/400 x 300 x 300mm (50m)/450 x 300 x 230mm (1.5m)/450 x 300 x 250mm (1m,2m,3m)/450 x 300 x 270mm (5m,10m)/450 x 300 x 290mm (0.5m)
Carton Q'ty	260pcs (0.25m)/300pcs (0.5m)/180pcs (1m)/120pcs (1.5m)/100pcs (2m)/80pcs (3m)/50pcs (5m)/40pcs (7.5m)/30pcs (10m)/15pcs (15m)/10pcs (20m)/8pcs (30-50m)
Carton Weight	5.7kg (0.25m)/9.2 (0.5m)/8.6kg (1m)/7.8kg (1.5m)/8kg (2m)/9.3kg (3m)/9.1kg (5m)/10.5kg (7.5m)/10.7kg (10m)/7.7kg (15m)/7.3kg (20m)/8.5kg (30m)/13kg (50m)

Packaging Informations (CQ3xx3S black)

Packing Dimension	120 x 160mm (0.25-0.5m)/140 x 180mm (1-1.5m)/160 x 200mm (2-3m)/180 x 230mm (5-7.5m)/200 x 240mm (10m)/200 x 240 x 100mm (15m)/220 x 260 x 100mm (20m)/260 x 300 x 100mm (30m)/300 x 330 x 100mm (50m)
Packing Weight	0.02kg (0.25m)/0.03kg (0.5m)/0.05kg (1m)/0.06kg (1.5m)/0.08kg (2m)/0.11kg (3m)/0.18kg (5m)/0.28kg (7.5m)/0.35kg (10m)/0.52kg (15m)/0.68kg (20m)/1.05kg (30m)/1.75kg (50m)
Carton Dimension	360 x 360 x 300mm (7.5m)/400 x 300 x 200mm (20m)/400 x 300 x 220mm (0.25m,15m)/400 x 300 x 230mm (30m)/400 x 300 x 300mm (50m)/450 x 300 x 230mm (1.5m)/450 x 300 x 250mm (1m,2m,3m)/450 x 300 x 270mm (5m,10m)/450 x 300 x 290mm (0.5m)
Carton Q'ty	260pcs (0.25m)/300pcs (0.5m)/180pcs (1m)/120pcs (1.5m)/100pcs (2m)/80pcs (3m)/50pcs (5m)/40pcs (7.5m)/30pcs (10m)/15pcs (15m)/10pcs (20m)/8pcs (30-50m)
Carton Weight	5.7kg (0.25m)/9.2 (0.5m)/8.6kg (1m)/7.8kg (1.5m)/8kg (2m)/9.3kg (3m)/9.1kg (5m)/10.5kg (7.5m)/10.7kg (10m)/7.7kg (15m)/7.3kg (20m)/8.5kg (30m)/13kg (50m)

www.logilink.de



Made in China

* The specifications and pictures are subject to change without notice.
*All trade names referenced are the registered trademark of their respective owners.

Packaging Informations (CQ3xx4S red/CQ3xx5S green/CQ3xx6S blue)

Packing Dimension	120 x 160mm (0.25-0.5m)/140 x 180mm (1-1.5m)/160 x 200mm (2-3m)/180 x 230mm (5-7.5m)/200 x 240mm (10m)
Packing Weight	0.02kg (0.25m)/0.03kg (0.5m)/0.05kg (1m)/0.06kg (1.5m)/0.08kg (2m)/0.11kg (3m)/0.18kg (5m)/0.28kg (7.5m)/0.35kg (10m)
Carton Dimension	360 x 360 x 300mm (7.5m)/400 x 300 x 220mm (0.25m)/450 x 300 x 230mm (1.5m)/450 x 300 x 250mm (1m,2m,3m)/450 x 300 x 270mm (5m,10m)/450 x 300 x 290mm (0.5m)
Carton Q'ty	260pcs (0.25m)/300pcs (0.5m)/180pcs (1m)/120pcs (1.5m)/100pcs (2m)/80pcs (3m)/50pcs (5m)/40pcs (7.5m)/30pcs (10m)
Carton Weight	5.7kg (0.25m)/9.2 (0.5m)/8.6kg (1m)/7.8kg (1.5m)/8kg (2m)/9.3kg (3m)/9.1kg (5m)/10.5kg (7.5m)/10.7kg (10m)

Packaging Informations (CQ3xx7S yellow/CQ3xx8S orange/CQ3xx9S Pink)

Packing Dimension	120 x 160mm (0.25-0.5m)/140 x 180mm (1-1.5m)/160 x 200mm (2-3m)/180 x 230mm (5-7.5m)/200 x 240mm (10m)
Packing Weight	0.02kg (0.25m)/0.03kg (0.5m)/0.05kg (1m)/0.06kg (1.5m)/0.08kg (2m)/0.11kg (3m)/0.18kg (5m)/0.28kg (7.5m)/0.35kg (10m)
Carton Dimension	360 x 360 x 300mm (7.5m)/400 x 300 x 220mm (0.25m)/450 x 300 x 230mm (1.5m)/450 x 300 x 250mm (1m,2m,3m)/450 x 300 x 270mm (5m,10m)/450 x 300 x 290mm (0.5m)
Carton Q'ty	260pcs (0.25m)/300pcs (0.5m)/180pcs (1m)/120pcs (1.5m)/100pcs (2m)/80pcs (3m)/50pcs (5m)/40pcs (7.5m)/30pcs (10m)
Carton Weight	5.7kg (0.25m)/9.2 (0.5m)/8.6kg (1m)/7.8kg (1.5m)/8kg (2m)/9.3kg (3m)/9.1kg (5m)/10.5kg (7.5m)/10.7kg (10m)

Packaging Informations (CQ3xxVS violet)

Packing Dimension	120 x 160 x 50mm (0.25-0.5m)/140 x 180 x 50mm (1-1.5m)/160 x 200 x 50mm (2-3m)/180 x 230 x 50mm (5-7.5m)/200 x 240 x 50mm (10m)
Packing Weight	0.02kg (0.25m)/0.03kg (0.5m)/0.05kg (1m)/0.06kg (1.5m)/0.08kg (2m)/0.11kg (3m)/0.18kg (5m)/0.28kg (7.5m)/0.35kg (10m)
Carton Dimension	360 x 360 x 300mm (7.5m)/400 x 300 x 220mm (0.25m)/450 x 300 x 230mm (1.5m)/450 x 300 x 250mm (1m,2m,3m)/450 x 300 x 270mm (5m,10m)/450 x 300 x 290mm (0.5m)
Carton Q'ty	260pcs (0.25m)/300pcs (0.5m)/180pcs (1m)/120pcs (1.5m)/100pcs (2m)/80pcs (3m)/50pcs (5m)/40pcs (7.5m)/30pcs (10m)
Carton Weight	5.7kg (0.25m)/9.2 (0.5m)/8.6kg (1m)/7.8kg (1.5m)/8kg (2m)/9.3kg (3m)/9.1kg (5m)/10.5kg (7.5m)/10.7kg (10m)

www.logilink.de



Made in China

* The specifications and pictures are subject to change without notice.
*All trade names referenced are the registered trademark of their respective owners.