


Data Sheet

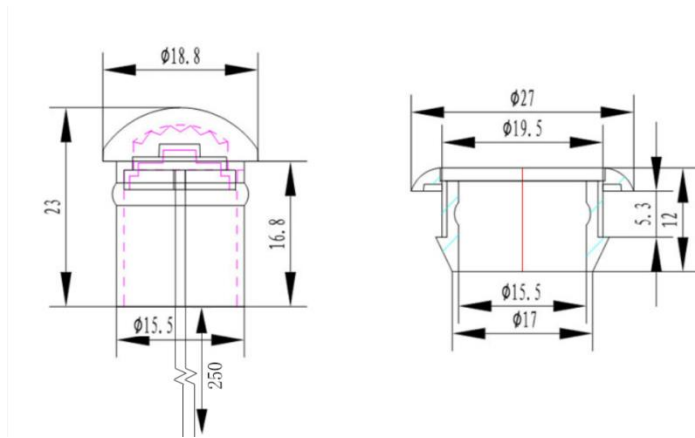

Voltage.....	12 V /DC
Light.....	3 inbuilt long life 3528 SMD LED's
Mounting hole.....	Dia. 19.5mm
Product dimension.....	Dia. 27 x 23 (H) mm
Color.....	Clear
Terminal.....	2 wires - 180 mm
Material.....	ABS/AS
Waterproof.....	IPX7
Operating Temperature.....	-40 to 70 °C
Storage Temperature.....	-40 to 90 °C
Operating & Storage Humidity.....	0 - 100%

"Not approved in the area of the StVZO."