



Digital HD Cable Receiver

SRT 3001



Picture similar

Digital cable TV in brilliant HD

The new SRT 3001 lets you enjoy digital Free-to-Air TV and radio programmes via cable in HD. Thanks to the built-in USB port you can share your favourite media as well as update your receiver software in no time. The SRT 3001 boasts with seamless audio and video quality and features Dolby® Digital Plus, multi-lingual subtitles and so much more. Enhance your viewing experience by adding the recording and Timeshift functions (available at our webshop). Exciting TV Entertainment at its best.

- HDTV receiver for digital Free-to-Air TV and radio programmes via cable¹
- Supports Dolby® Digital Plus²
- Quick and easy installation & user-friendly menu
- Parental lock function for menu
- USB port for playback of multimedia files³ and receiver software updates via USB storage device

- User-friendly remote control
- Electronic TV Programme Guide (EPG) for on screen programme information of present/following event information up to 7 days⁴
- Excellent audio and video quality
- Multi-lingual support on screen menu (OSD)



Digital HD Cable Receiver SRT 3001

- HDTV receiver for digital Free-to-Air TV and radio programmes via cable¹
- Supports Dolby® Digital Plus²
- Quick and easy installation & user-friendly menu
- Parental lock function for menu
- USB port for playback of multimedia files³ and receiver software updates via USB storage device
- User-friendly remote control
- Electronic TV Programme Guide (EPG) for on screen programme information of present/following event information up to 7 days⁴
- Excellent audio and video quality
- Multi-lingual support on screen menu (OSD)
- Teletext, full multi-lingual DVB subtitling and audio track support⁴
- 8 favourite lists for TV and radio programmes
- 8 event timers with 4 modes (once, daily, weekly, monthly)
- 1000 channels memory capacity


- HD on screen display (OSD)
- Booking of events directly from EPG
- Automatic and manual channel scan options
- Digital sound via coaxial output (S/PDIF) by connecting to digital amplifier
- USB power control for power saving in standby mode
- Fast channel zapping
- Power saving automatic standby function
- Channel handling options: lock, edit, move, sort, skip, delete and rename
- Power on with last viewed channel
- **Connectors:** Cable IN, Cable OUT, S/PDIF (coaxial), HDMI, TV SCART, USB

¹ Depending on local signal conditions

² Dolby Digital Plus and the double-D symbol are registered trademarks of Dolby Laboratories.

³ STRONG cannot guarantee the playback of all files although extensions are listed, as it depends on codec used, data bit rate and resolution (all MPEG codec formats are supported).

⁴ Availability depending on broadcaster

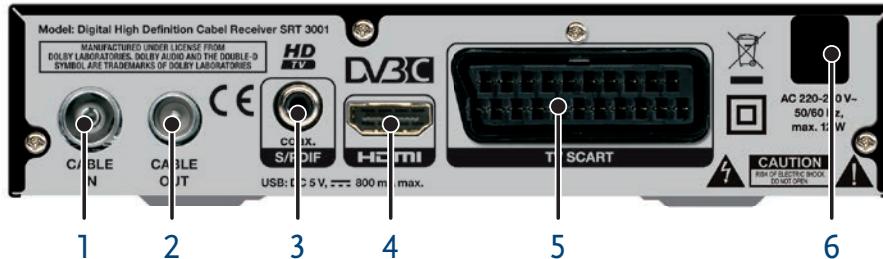

Picture similar

1. Cable	4. TV (HDMI)
2. TV/receiver (coax.)	5. TV (SCART)
3. Digital audio amplifier (coax.)	6. Power cord

Tuner

Tuner: SONY 2872
Input Impedance: 75 Ohm
Minimum Input Level: ≤ 40 dBuV (64 QAM)
≤ 44 dBuV (256 QAM)
Receiving Channel Range: 46 MHz ~ 862 MHz
Modulation: 64 QAM/256 QAM
Symbol rate: 3.6 M ~ 6.952 MS/s (64 QAM)

Video

Video decoder: MPEG -2 MP@HL, AVC/H.264 HP@L4.1, MPEG-4 ASP supported
Video resolution: 480i, 480p, 576i, 576p, 720p, 1080i, 1080p, By Source, By Native TV
Decoding & Video Out: PAL
Aspect ratio: 4:3 Letterbox, 4:3 Pan & Scan, 16:9, Auto

Audio

Audio support: AC3+/PCM/Dolby® Digital Plus*
Audio mode: Stereo, Mono

System

Transponder: DVB-C (Digital Cable)
Main Processor: Ali M3812
Demodulator: Sony D2837ER
Memory: DDR II 64 MB
FLASH size: 4 MB

Connectors

Cable IN - IEC Female
Cable OUT - IEC Male (Loop through)
S/PDIF (coaxial)
HDMI
TV SCART
USB 2.0 port : DC 5 V, 800 mA (max.) supported

General Data

Supply voltage: 220 - 240 V AC (SMPS), 50/60 Hz
Power consumption: 5.14 W (typ.) 12 W (max.)
Power consumption in standby: max. 0.7 W
Operating temperature: 0 ~ +40 °C
Storage temperature: -10 ~ +50 °C
Operating humidity range: 10 ~ 85%, RH, Non-condensing
Size (WxDxH) in mm: 170 x 113 x 40
Weight in kg: 0.34

* Dolby Digital Plus and the double-D symbol are registered trademarks of Dolby Laboratories.

EAN SRT 3001: 9120072370137

SERVICE CENTER

AT  support_at@strong.tv	DE  support_de@strong.tv
IT  support_it@strong.tv	IT  199.404.002 Da rete fissa 24,8 cent. al min. 12,5 cent. scatto alla risposta Da rete fissa 49 cent. al min. 15,6 cent. scatto alla risposta
BG  support_bg@strong.tv	DK  support_dk@strong.tv
CEE  support_hu@strong.tv	FR  support_fr@strong.tv

IT  support_it@strong.tv
NL  support_nl@strong.tv
PL  support_pl@strong.tv
UA  support_ua@strong.tv

STRONG declares that this item complies with the basic requirements and other relevant regulations of directives

CE 2004/108/EC and 73/23/EC, RoHS 2002/95/EC

Subject to alterations. In consequence of continuous research and development technical specifications, design and appearance of products may change. HDMI, the HDMI logo and High-Definition Multimedia Interface are trademarks or registered trademarks of HDMI Licensing LLC in the United States and other countries. Manufactured under license from Dolby Laboratories. Dolby Audio, Dolby Digital, Dolby Digital Plus and the double-D symbol are registered trademarks of Dolby Laboratories. All other product names are trademarks or registered trademarks of their respective owners. © STRONG 2016. All rights reserved.