

# LogiLink®



## Wireless Keypad

Art. No.: ID0120

Compact size 18 keys wireless numeric keyboard.

### Features:

- » 2.4GHz FSK technology
- » 34 two way R F channels
- » 6~10 Meter working range
- » Nano receiver on keyboard

### Specification:

Interface	USB 1.1/ USB2.0
Battery Type	one AAA Battery
Battery Consumption	Keyboard: Operating Mode: $\leq 4$ mA Sleep Mode 1: $\leq 44$ uA
Sensor Report Rate on Mouse	3000 times per second
Operation Angle	360 degrees
Operation Distance	6~10 meter for keyboard and mouse
Sensor Light	Red
Receiver Power Requirement	5V DC from USB port
R F Frequency	2.4 Ghz (2.408~2.474 Ghz)
R F Modulation	F S K
Hopping Type	FHSS (frequency hopping spread spectrum)
R F Bandwidth	2MHz
Speed of Transmit	375k bps
R F Output Power	0 dBm
Receive of Sensitive	-85 dBm
Keyboard Button Switch Activation	8,000,000 cycle
System Requirement	Windows 2000/XP/ME/VISTA/7/8/10
Product Dimension	82 x 124 x 22mm
Product Weight	70g

Best Connectivity



RoHS  
compliant



\* The specifications and pictures are subject to change without notice.  
\*All trade names referenced are the registered namework of their respective owners.




Made in China

# LogiLink®

## Wireless Keypad

Art. No.: ID0120

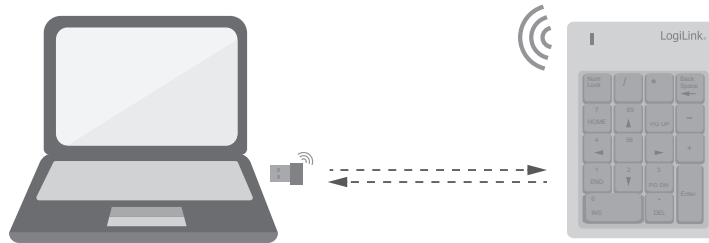

### Package Contents:

- » 1 x Wireless Keypad
- » 1 x User Manual

### Package Informations:

- » Packing Dimension: 210 x 140 x 60mm
- » Packing Weight: 0.16kg
- » Carton Dimension: 465 x 325 x 305mm
- » Carton Q'ty: 40pcs
- » Carton Weight: 6.5kg



ID0120



Made in China



RoHS  
compliant



\* The specifications and pictures are subject to change without notice.  
\* All trade names referenced are the registered namework of their respective owners.