

Overvoltage protection aluminum socket strip 5-fold with switch

Item-No.: 0606x00052031 (1,5 m cord)



Noble, transparent anodized aluminum case, matt

Built-in sockets (90° rotated), round

Extra large space in between sockets 64 mm

1,5 m power cord and angle plug (optional with 3 m or 5 m power cord)

Increased safety due to integrated child protection

End caps with mounting possibility


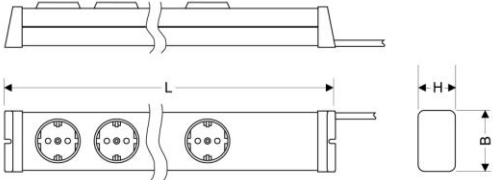
Optical function display and acoustic fault message

EHMANN advantage - the connected devices will remain in operation after release of overvoltage protection



Overvoltage protection aluminum socket strip 5-fold with switch

Technical data

3.600 W Power	250 V ~ / 50 Hz Rated voltage	16 A Rated current
Power Cord: H05VV-F 3G 1,5 mm ² Plug: CEE 7/7 plug Type EF, angled Sockets: earthing contact Type F Switch: 2-pole, illuminated Consumption per switch: < 0,4 W Voltage U _n : 230 V~ Max. continuous operation voltage U _c : 255 V~ U _{oc} : 5000 V Protection level Up: L-N < 1,0kV - L/N-PE < 1,5kV I _{max} (8/20): 6,5 kA SPD according to EN 61643-11: Typ3 Consumption overvoltage protection: < 0,1 W Safety class: IP20		
 <p>(similar illustration)</p>		
Item-No. 0606x00052031 (1,5m cord) EAN 401209600600 8 PU10		458 x 65 x 43 mm Dimensions (L x B x H) 452 mm Fixing Dimension