

According to EU-Regulation no. 2019/2015

Article-No.: LM85249-2

**Decolight
(LIGHTME) Deco LED 1W-E27/827 (IP44)**

EAN-Code: 4020856852499



General Properties

| | |
|-----------------------------|------------------|
| Lamp Base | E27 |
| Nominal Life | 15.000 Std. |
| Rated Life | 15.000 Std. |
| Switching Cycles | 40.000x |
| Operating Temperature | -20°C bis +40° C |

Environmental Properties

| | |
|------------------------------|---|
| Luminaire Energy Label | G |
|------------------------------|---|

Energy Efficiency Label

According to Regulation 2019/2015



Product Measurements

| | |
|----------------|-------|
| Length | 69 mm |
| Diameter | 45 mm |
| Weight | 14 g |

Electrical Properties

| | |
|--|---------------|
| Voltage | 220-240 V |
| Network Frequency | 50-60 Hz |
| Wattage | 1,0 W |
| Rated Wattage | 1,0 W |
| Weighted energy consumption | 1 kWh/1.000 h |
| Power Factor | k.A. |
| Dimmable? | No |
| Ignition | < 0,5 s |
| Starting Time ¹ | Instant |
| Mercury content ² | 0,0 mg |
| Equivalence Wattage ³ | 9 W |

Light Properties

| | |
|--------------------------------------|-----------|
| Color Code | 827 |
| Light Color | Warmwhite |
| Color Temperature | 2700 K |
| CRI | Ra 80 |
| Nominal luminous flux | 70 lm |
| Lumen maintenance ⁴ | 70 % |
| Color Consistency SDCM | ≤ 6 |

¹ until reaching 60% luminous flux

² bound as an amalgam

³ a conventional illuminant of the same type

⁴ at the end of the rated life

According to EU-Regulation no. 2019/2015

Notes and Recommendations

Recommendation for the disposal of the luminaire

– <http://www.lightme.eu/oekodesign/entsorgung/index.html>

Note

– Special lamp for decoration purposes, not intended for room lighting in the home!


Line Drawing
LED LM85249-2



H: 69 mm

D: 45 mm

Line Drawing
Equivalent-Lamp

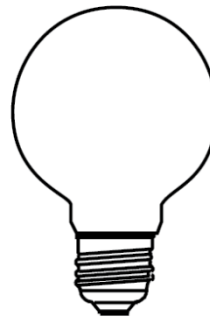

H: 73 mm

D: 45 mm

Color Spectrum

