


KERN EWJ300-3

Hochwertige Präzisionswaage mit interner Justierautomatik und Eichzulassung [M]

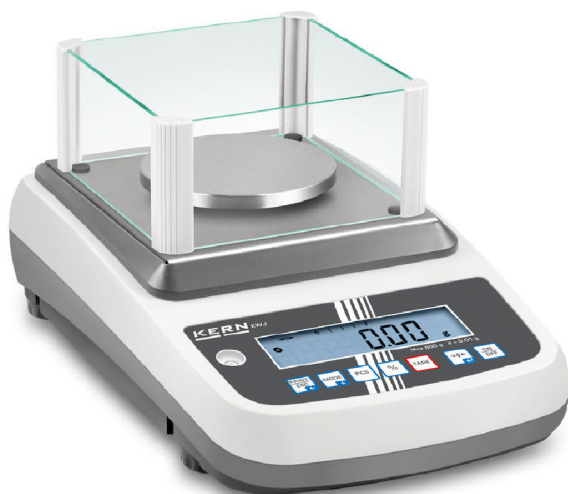

Environmental conditions

Maximum humidity:	80 %
Maximum operating temperature:	35 °C
Minimum ambient temperature:	15 °C

Power supply

Charging time:	4 h
n/a:	CH EURO UK US

n/a:	Mains adapter external
------	------------------------

Power supply

Operating time (Backlight off):	15 h
Operating time (Backlight on):	10 h
Rechargeable battery:	Rchrg. battery optional - intern

Service

DAkkS Certificate:	963-127
--------------------	---------

Category

Brand:	KERN
Category:	Balances
Product Group:	Precision balance

Packaging & shipping

Delivery:	24 h
Dimensions packaging (WxDxH):	390 x 280 x 175 mm
Gross weight:	3,800 kg
Net weight:	2,470 kg
Shipping method:	Parcel service

Construction

Casing material:	Plastic
Dimensions draft shield (WxDxH):	158 x 143 x 82 mm
Dimensions housing (WxDxH):	220 x 315 x 90 mm
Level indicator:	yes
Material weighing plate:	stainless steel
Overall dimensions mounted (WxDxH):	220 x 315 x 180 mm
Revolving screw feet:	yes
Weighing space (WxDxH):	145 x 160 x 80 mm
Weighing surface (d):	80

Measuring system

Adjustment options:	Internal calibration (auto)
Linearity:	3 mg
n/a:	4 g
Readout [d]:	1 mg
Recommended adjusting weight:	300 g (F1)
Reproducibility:	2 mg
Resolution:	300000
Stabilisation time:	3 s
Tare range:	300 g
Warm up time:	2 h
Weighing range [Max]:	300 g
Weighing system:	Strain gauge
Weighing units:	ct dwt lb mo oz ozt tl (HK) tl (Singap. Malays) tl (Tw)

Display

Display digit height:	1,650 cm
-----------------------	----------

Counting

Counting resolution:	150000
Minimum piece weight at piece counting (Laboratory):	2 mg
Minimum piece weight at piece counting (Normal):	20 mg

Functions

Capacity display:	yes
Counting function:	yes
Function to save totals:	yes
Percentage determination:	yes