


# KERN BIC3T-3L

Hochauflösende Bodenwaage mit 2x3000 [d] und top Preis-Leistungs-Verhältnis

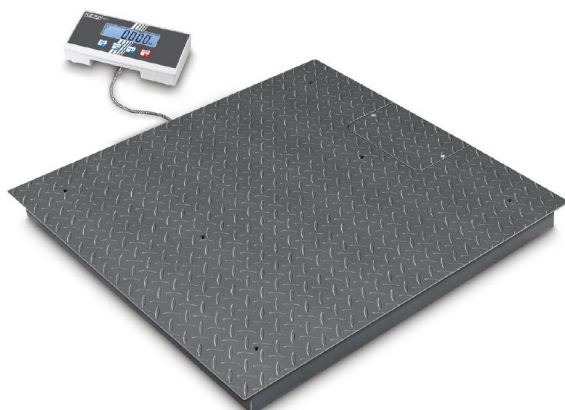

## Measuring system

Adjustment options:	External calibration
Linearity:	1,500 kg   3 kg
Readout [d]:	500 g   1000 g
Recommended adjusting weight:	3000 kg (M2)
Reproducibility:	500 g   1000 g
Resolution:	3 3.000
Stabilisation time:	2 s
Tare range:	-3000000000 mg
Warm up time:	10 min   10 min
Weighing range [Max]:	1,500 t   3 t
Weighing system:	Strain gauge
Weighing units:	g kg lb oz

## Display

Display digit height:	2,500 cm
-----------------------	----------

## Environmental conditions

Maximum humidity:	80 %
Maximum operating temperature:	40 °C
Minimum ambient temperature:	-10 °C
Minimum humidity:	0 %

## Power supply

Input voltage:	100 V - 240V AC 50/60Hz 0.3A
n/a:	AUS EURO UK US

n/a:	Mains adapter external
------	------------------------

## Power supply

Operating time:	60 h
-----------------	------

## Service

Adjustment at the location of installation: 961-252

DAkkS Certificate: 963-132

## Category

Brand:	KERN
Category:	Balances
Product Group:	Floor scale

## Packaging & shipping

Delivery:	48 h
Dimensions packaging (WxDxH):	1550 x 1550 x 265 mm
Gross weight:	200 kg
Net weight:	150 kg
Shipping method:	Freight forwarder

## Construction

Cable length:	5 m
Cable length of display device:	5 m
Dimensions (WxDxH):	1500 x 1500 x 108 mm
Dimensions of display device (WxDxH):	235 x 114 x 51 mm
Dimensions of weighing plate (WxDxH):	1500 x 1500 x 108 mm
Level indicator:	yes
Revolving screw feet:	yes
Weighing surface (WxD):	1500 x 1500 mm