

KERN[®]

KERN & Sohn GmbH

Ziegelei 1
D-72336 Balingen
E-Mail: info@kern-sohn.com

Tel: +49-[0]7433- 9933-0
Fax: +49-[0]7433-9933-149
Internet: www.kern-sohn.com

Montageanleitung Auffahr-Rampe
Instruction of Assembly Access Ramp
Instruction de montage Rampe de montée
Instrucción de montaje Rampa de subida
Istruzione di montaggio Rampa d'accesso
Montageaanwijzing Oprijplaat
Instrukcja montażu Rampa najazdowa
Montážní instrukce Nájezdová rampa
Инструкция по монтажу Подъездная аппарель
Instrução de montagem Rampa de acesso

KERN

BFS-A01 / A02 / A09 / A11 / BFN-A01-A05

Version 3.1

11/2014

D-GB-F-E-I

NL-PL-CZ-RUS-P


(BFS-A01)



BFS-A01/A02/A09/A11_BFN-A01/A05-IA-multi-1431

KERN®

D Abbildung ähnlich GB Figure approximately F Figure d'environ
 E Figura aproximadamente I Figura circa NL Figuur ongeveer PL Rysunek około
 CZ Obrázek přibližně RUS Рис примерно P Figura aproximadamente

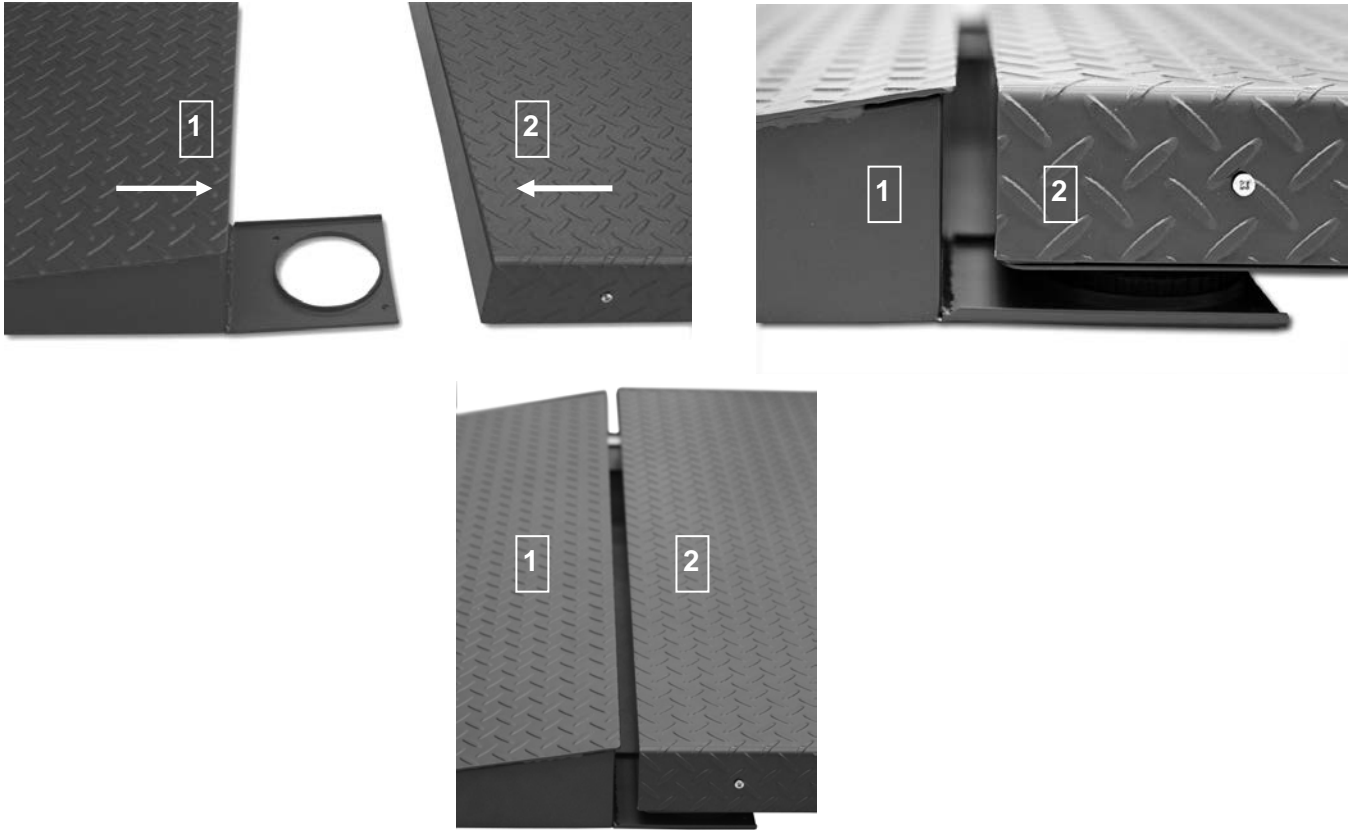

	1	2
D	Auffahr-Rampe	Wägebrücke
GB	Access ramp	Platform
F	Rampe	Pont de bascule
E	Rampa	Puente de báscula
I	Rampa d'accesso	Ponte della bilancia
NL	Oprijplaat	Weegschaalplatform
PL	Rampa najazdowa	Pomost wagi
CZ	Rampa	Můstek
RUS	Подъездная аппарель	Грузоприемное устройство
P	Rampa de acesso	Ponte de pesagem

BFS-A01

D	Maße (mm)	B x T x H 1000 x 750 x 85
GB	Dimensions	S x G x W 1000 x 750 x 85
F	Dimensions	S x G x W 1000 x 750 x 85
E	Dimensiones	S x G x W 1000 x 750 x 85
I	Dimensione	L x G x A 1000 x 750 x 85
NL	Afmetingen	S x G x W 1000 x 750 x 85
PL	Wymiary	S x G x W 1000 x 750 x 85
CZ	Rozměr	Š x H x V 1000 x 750 x 85
RUS	Размеры	Ш x Г x B 1000 x 750 x 85
P	Medidas	L x P x A 1000 x 750 x 85

BFS-A02

D	Maße (mm)	B x T x H 1250 x 750 x 85
GB	Dimensions	S x G x W 1250 x 750 x 85
F	Dimensions	S x G x W 1250 x 750 x 85
E	Dimensiones	S x G x W 1250 x 750 x 85
I	Dimensione	L x G x A 1250 x 750 x 85
NL	Afmetingen	S x G x W 1250 x 750 x 85
PL	Wymiary	S x G x W 1250 x 750 x 85
CZ	Rozměr	Š x H x V 1250 x 750 x 85
RUS	Размеры	Ш x Г x B 1250 x 750 x 85
P	Medidas	L x P x A 1250 x 750 x 85

BFS-A09

D	Maße (mm)	B x T x H 1500 x 750 x 85
GB	Dimensions	S x G x W 1500 x 750 x 85
F	Dimensions	S x G x W 1500 x 750 x 85
E	Dimensiones	S x G x W 1500 x 750 x 85
I	Dimensione	L x G x A 1500 x 750 x 85
NL	Afmetingen	S x G x W 1500 x 750 x 85
PL	Wymiary	S x G x W 1500 x 750 x 85
CZ	Rozměr	Š x H x V 1500 x 750 x 85
RUS	Размеры	Ш x Г x B 1500 x 750 x 85
P	Medidas	L x P x A 1500 x 750 x 85

BFS-A11

D	Maße (mm)	B x T x H 1500 x 750 x 121
GB	Dimensions	S x G x W 1500 x 750 x 121
F	Dimensions	S x G x W 1500 x 750 x 121
E	Dimensiones	S x G x W 1500 x 750 x 121
I	Dimensione	L x G x A 1500 x 750 x 121
NL	Afmetingen	S x G x W 1500 x 750 x 121
PL	Wymiary	S x G x W 1500 x 750 x 121
CZ	Rozměr	Š x H x V 1500 x 750 x 121
RUS	Размеры	Ш x Г x B 1500 x 750 x 121
P	Medidas	L x P x A 1500 x 750 x 121

BFN-A01

D	Maße (mm)	B x T x H 1250 x 750 x 85
GB	Dimensions	S x G x W 1250 x 750 x 85
F	Dimensions	S x G x W 1250 x 750 x 85
E	Dimensiones	S x G x W 1250 x 750 x 85
I	Dimensione	L x G x A 1250 x 750 x 85
NL	Afmetingen	S x G x W 1250 x 750 x 85
PL	Wymiary	S x G x W 1250 x 750 x 85
CZ	Rozměr	Š x H x V 1250 x 750 x 85
RUS	Размеры	Ш x Г x B 1250 x 750 x 85
P	Medidas	L x P x A 1250 x 750 x 85

BFN-A05

D	Maße (mm)	B x T x H 1000x750x85
GB	Dimensions	S x G x W 1000x750x85
F	Dimensions	S x G x W 1000x750x85
E	Dimensiones	S x G x W 1000x750x85
I	Dimensione	L x G x A 1000x750x85
NL	Afmetingen	S x G x W 1000x750x85
PL	Wymiary	S x G x W 1000x750x85
CZ	Rozměr	Š x H x V 1000x750x85
RUS	Размеры	Ш x Г x B 1000x750x85
P	Medidas	L x P x A 1000x750x85