


KERN BIC1T-4S

Hochauflösende Bodenwaage mit 2x3000 [d] und top Preis-Leistungs-Verhältnis

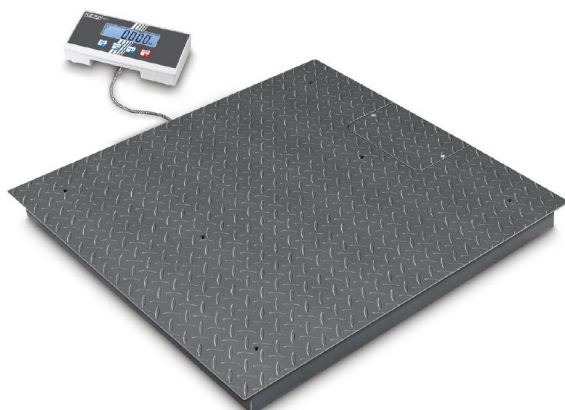

Measuring system

Adjustment options:	External calibration
Linearity:	1 kg
Readout [d]:	200 g 500 g
Recommended adjusting weight:	1500 kg (M2)
Reproducibility:	500 g
Resolution:	3 3.000
Stabilisation time:	2 s
Tare range:	-1500000000 mg
Warm up time:	10 min 10 min
Weighing range [Max]:	600 kg 1500 kg
Weighing system:	Strain gauge
Weighing units:	g kg lb oz

Display

Display digit height:	2,500 cm
-----------------------	----------

Environmental conditions

Maximum humidity:	80 %
Maximum operating temperature:	40 °C
Minimum ambient temperature:	-10 °C
Minimum humidity:	0 %

Power supply

Input voltage:	100 V - 240V AC 50/60Hz 0.3A
n/a:	AUS EURO UK US

n/a:	Mains adapter external
------	------------------------

Power supply

Operating time:	60 h
-----------------	------

Service

Adjustment at the location of installation: 961-250

DAkkS Certificate: 963-130

Category

Brand:	KERN
Category:	Balances
Product Group:	Floor scale

Packaging & shipping

Delivery:	48 h
Dimensions packaging (WxDxH):	1050 x 1050 x 260 mm
Gross weight:	150 kg
Net weight:	130 kg
Shipping method:	Freight forwarder

Construction

Cable length:	5 m
Cable length of display device:	5 m
Dimensions (WxDxH):	1200 x 1000 x 108 mm
Dimensions of display device (WxDxH):	235 x 114 x 51 mm
Dimensions of weighing plate (WxDxH):	1000 x 1000 x 108 mm
Level indicator:	yes
Revolving screw feet:	yes
Weighing surface (WxD):	1000 x 1000 mm