


# KERN KFD600V20LM

Wägebrücke mit IP67-Schutz mit zwei integrierten Auffahrampen

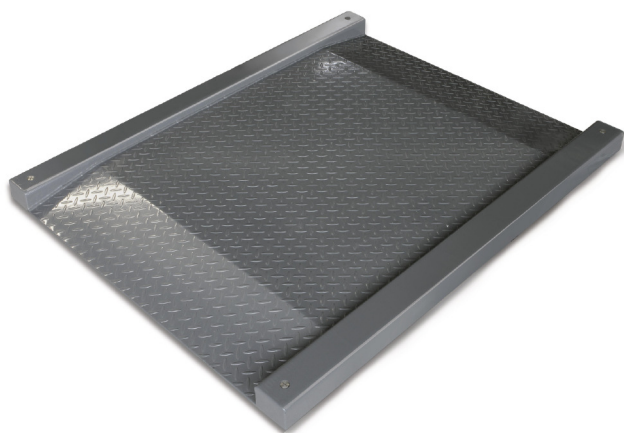

Material weighing plate:	Steel lacquered
Weighing surface (WxD):	1800 x 1200 mm

## Measuring system

Readout [d]:	200 g
Resolution (non verifiable):	3000
Weighing range [Max]:	600 kg

## Technical data about verification

Minimum load [Min]:	4 kg
Verification by KERN possible:	yes
Verification value [e]:	200 g

## Service

Adjustment at the location of installation: 961-250

DAkkS Certificate:	963-130
Verification:	965-230

## Category

Brand:	KERN
Category:	Platforms
Product Group:	Weighing bridge

## Packaging & shipping

Delivery:	48 h
Dimensions packaging (WxDxH):	1400 x 1800 x 330 mm
Gross weight:	192 kg
Net weight:	154 kg
Shipping method:	Freight forwarder

## Construction

Cable length:	5 m
Cable length of display device:	5 m
Dimensions of weighing plate (WxDxH):	1400 x 1800 x 80 mm