




1 KERN KFA-V20 IP67 Weighing beams

Features


- Weighing beams, lacquered steel
- 4 load cells, alloy steel, silicone-coated, IP67
- Levelling feet for precise levelling of the weighing beams
- Cable length between weighing beams approx. 5 m
- KFA 600V20S: Model with short weighing beams, ideal for weighing compact items or animals in transport boxes

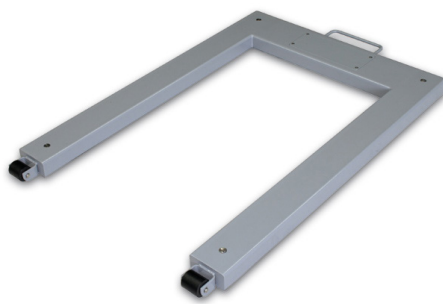

2 KERN KFU-V20/V30 IP67 U-Weighing bridge

Features

- KERN KFU-V20: Load range: painted steel (V20), stainless steel (V30) height 90 mm (see larger picture)
- **A** KERN KFU-V30: Load range: stainless steel
- 4 load cells, alloy steel, silicone-coated, IP67, OIML R60 approval for verification, Class III, 3000 e
- 2 rollers and handle for easy transport of the scale

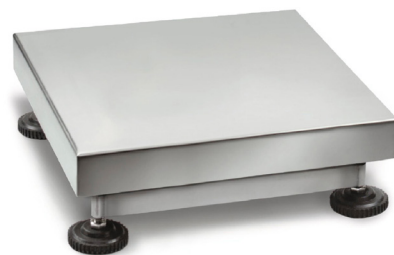


3 KERN KFP-V30 IP67 Platform

Features

- Platform: entirely out of stainless steel, **B** Painted steel base
- 1 weighing cell, stainless steel, silicone-coated, IP67, OIML R60 approval for verification, class III, 3000 e
- Level indicator and levelling feet for precise levelling of the scale, fitted as standard

 Discover more details and matching accessories online!



Model	Weighing capacity [Max] kg	Readability [d] g	Verification value [e] g	Minimal load [Min] g	Cable length approx. m	Net weight approx. kg	Weighing plate W×D×H mm
KERN							
1 Weighing beams KFA-V20 IP67							
KFA 600V20S	600	200	-	-	5	32	870×170×83
KFA 1500V20	1500	500	-	-	5	38	1270×170×83
KFA 3000V20	3000	1000	-	-	5	36	1270×170×83
KFA 3000V20L	3000	1000	-	-	5	55	2091×120×83
KFA 6000V20	6000	2000	-	-	5	80	1270×160×115
KFA 6000V20L	6000	2000	-	-	5	125	2091×160×115
2 U-Weighing bridge KFA-V20 IP67							
KFU 600V20M	600	200	200	4000	5	55	1361×840×80
KFU 1500V20M	1500	500	500	10000	5	55	1361×840×80
2 U-shaped stainless steel weighing bridge KFU-V30 IP67							
KFU 600V30M	600	200	200	4000	5	55	1361×840×80
KFU 1500V30M	1500	500	500	10000	5	55	1361×840×80
3 Stainless steel platform KFP-V30 IP67							
KFP 15V30M	15	1	5	100	3	8	300×240×107
KFP 30V30SM	30	2	10	200	3	5,0	300×240×107
KFP 30V30M	30	2	10	200	3	8	400×300×111
KFP 60V30M	60	5	20	400	3	8	400×300×111
KFP 60V30LM	60	5	20	400	2,5	10	500×400×120
KFP 60V30XLM	60	5	20	400	2,5	22	650×500×139
KFP 150V30SM	150	10	50	1000	3	10	400×300×111
KFP 150V30M	150	10	50	1000	3	10	500×400×120
KFP 150V30LM	150	10	50	1000	2,5	22	650×500×139
KFP 300V30M	300	20	100	2000	3	22	650×500×139