


# KERN KFU600V20M

U-Wägebrücke

**KERN**<sup>®</sup>

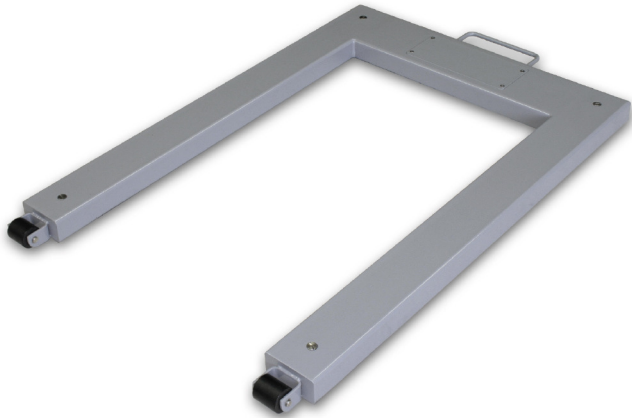

## Measuring system

Readout [d]:	200 g
Resolution (non verifiable):	3000
Weighing range [Max]:	600 kg

## Technical data about verification

Minimum load [Min]:	4 kg
Verification by KERN possible:	yes
Verification value [e]:	200 g

## Service

Adjustment at the location of installation: 961-250

DAkkS Certificate:	963-130
Verification:	965-230

## Category

Brand:	KERN
Category:	Platforms
Product Group:	Platform

## Packaging & shipping

Delivery:	48 h
Dimensions packaging (WxDxH):	138 x 85 x 28 mm
Gross weight:	84 kg
Net weight:	52 kg
Shipping method:	Freight forwarder

## Construction

Cable length:	5 m
Dimensions of weighing plate (WxDxH):	840 x 1300 x 90 mm
Material weighing plate:	Metal lacquered
Revolving screw feet:	yes