



OZB-A1201




OZB-A1203



OZB-A6302



OZB-A1211

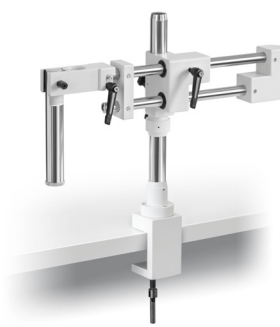

OZB-A1213



OZB-A6303



OZB-A6301

ECO universal stands

Features

- With our universal stands and basic stands, as well as microscope heads and external illumination units, you can configure your microscope to your own specifications and adapt it to your application
- Thanks to the versatile, adjustable universal stands it is possible to work in the very best way in all areas with the most varied of samples

- Small universal stands are available as stand base variants as well as with the option of a clamp for the edge of a bench. Depending on the model, you have the choice of a telescopic arm stand or a telescopic double arm universal stand with ball bearings
- The spring loaded universal stands including bench clamp will make your daily work with your stereo microscope easier. Now including coarse adjustment knob for easy, flexible focussing

Technical data

OZB-A1201/OZB-A1211

- Column height: 430 mm
- Length telescopic arm: 385 mm

OZB-A1203/OZB-A1213

- Column height: 430 mm
- Length telescopic arm: 480 mm

OZB-A6302

- Height spring loaded arm: 525 mm
- Length spring loaded arm: 620 mm

OZB-A6301

- Column height: 300 mm

OZB-A6303

- Height spring loaded arm: 400 mm
- Length spring loaded arm: 850 mm

Model	Description
-------	-------------

KERN

OZB-A1201	Telescopic arm – Plate – excl. holder
OZB-A1211	Telescopic arm – Clamp Edge of bench (Range: max. 40 mm) – excl. holder
OZB-A1203	Jointed arm – Plate – excl. holder
OZB-A1213	Jointed arm – Clamp Edge of bench (Range: max. 40 mm) – excl. holder
OZB-A6302	Spring loaded arm (Pneumatic spring) – Clamp (Range: max. 50 mm) – with holder (Coarse focusing knob)
OZB-A6303	Spring loaded arm (Compression spring) – Clamp (Range: max. 50 mm) – with holder (Coarse focusing knob)
OZB-A6301	Pillar style stand with “C”-shape base – excl. holder