



Your Personal Connection

2.5 Heavy-wall heat shrink tubing

HRA3 and HR3

Heavy-wall heat shrink tubing / with and without hot melt adhesive

Features:

- Heavy-wall tubing with and without hot melt adhesive
- Superior electrical and environmental insulation
- Excellent abrasion and impact resistance
- Ideal for low voltage applications
- UV resistant

Approvals:


- Meets: RoHS

Application:

- Operating temperature: -55 °C to +125 °C
- Minimum full recovery temperature: +120 °C
- Longitudinal change: 0 ± 10% max.

Order information:

- Also available in lengths of 1 and 1,5 meter
- Color: black

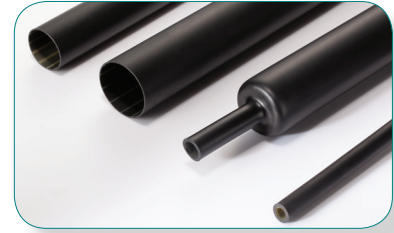

Type / Size	As supplied: inside diameter in mm (min.)	After recovery: inside diameter in mm (max.)	After recovery: wall thickness in mm (min.)	Standard length in mm
HRA3/HR3 9/3	9,0	3,0	1,8	1220
HRA3/HR3 13/4	13,0	4,0	2,2	1220
HRA3/HR3 22/6	22,0	6,0	2,7	1220
HRA3/HR3 33/8	33,0	8,0	3,2	1220
HRA3/HR3 40/12	40,0	12,0	4,0	1220
HRA3/HR3 45/12	45,0	12,0	4,0	1220
HRA3/HR3 55/16	55,0	16,0	4,0	1220
HRA3/HR3 65/19	65,0	19,0	4,0	1220
HRA3/HR3 75/22	75,0	22,0	4,0	1220
HRA3/HR3 85/25	85,0	25,0	4,2	1220
HRA3/HR3 95/30	95,0	30,0	4,2	1220
HRA3/HR3 105/30	105,0	30,0	4,2	1220
HRA3/HR3 115/34	115,0	34,0	4,2	1220
HRA3/HR3 130/36	130,0	36,0	4,2	1220
HRA3/HR3 160/50	160,0	50,0	4,2	1220
HRA3/HR3 180/50	180,0	50,0	4,2	1220
HRA3/HR3 200/60	200,0	60,0	4,2	1220
HRA3/HR3 235/65	235,0	65,0	4,1	1220
HRA3/HR3 265/75	265,0	75,0	4,3	1220
HRA3/HR3 300/85	300,0	85,0	4,4	1220
HRA3/HR3 350/100	350,0	100,0	4,5	1220

For selecting the right type of heat shrink tubing (selection table), please see page 66
For cross references, please see page 68