



## Data Sheet

### “Master Connector IP68” Typ MC001

Art-Nr.: 3400 068

Seite 1 von 1

Safe and quick protection of cables. Suitable for wet zones and subterranean applications due to its special sealing. The lamellar construction ensures easy handling and makes it possible to connect two cables even with different diameters between 6 – 13 mm without difficulties. The Master Connector IP 68 can replace expensive and complex cast parts and is therefore an economic and quick alternative.  
According to DIN VDE 0606-1




#### Technical data:

Nominal cross-section:	2.5 mm <sup>2</sup>
Nominal voltage:	400 V
Number of poles of the luster terminal:	3 poles
Cable diameter:	6 - 13 mm (up to H07RN-F 3G2.5 mm <sup>2</sup> )
Temperature range:	-20°C to 80°C (Luster terminal up to 100°C)
Protection class:	IP 68 - 5 bar
Wrench size:	24

#### Approbations:



#### Dimensions:

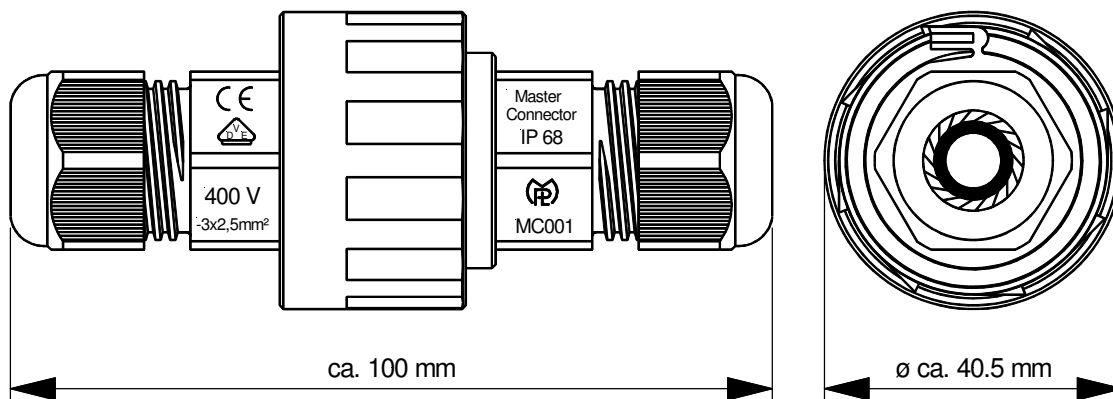

Müller Plastik GmbH – Alte Bahnhofstrasse 21 – 51688 Wipperfürth – Internet: [www.mueller-plastik.de](http://www.mueller-plastik.de)  
Tel.: +49 (0) 22 67 / 88 40 -0 Fax: +49 (0) 22 67 / 88 40 -33 E-mail: [info@mueller-plastik.de](mailto:info@mueller-plastik.de)