
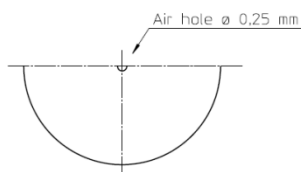


mercury free

**ecopack**

## Data sheet 10 mercury free

---

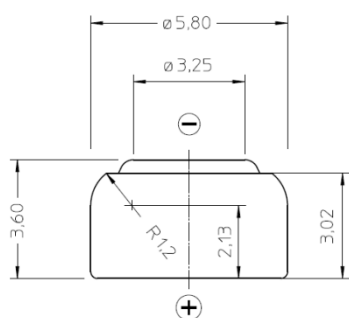

### Specifications:

Chemical system:	Zinc / Air
Nominal voltage:	1,45 V
Standard Capacity:	95 mAh**
Impedance:	max. 12Ω@ 1kHz
Weight:	approx 0,3 g
Volume:	approx 0,085 ccm
Storage:	10-30° C / 20-80 % r.h.
Operating:	0-45° C / 25-70 % r.h.
Short Exposition:	-10-65° C / 5-95 % r.h.

\*\*3000 Ohms 12h/day to 1.1V at 21° C / 60% r.h.

### Dimensions:

according to IEC 60086-2 Feb. 2011 (12th Edition)  
IEC: PR 70

VARTA Microbattery GmbH  
Daimlerstraße 1  
D 73479 Ellwangen  
Tel.: +49 7961 921 0  
[www.varta-microbattery.com](http://www.varta-microbattery.com)

This data is subject to change without prior notice. Performance information is typical. Contact VARTA for latest information. March 2011