

Product Code:

LPT9018BS-HL-03-4.0-12-R-1

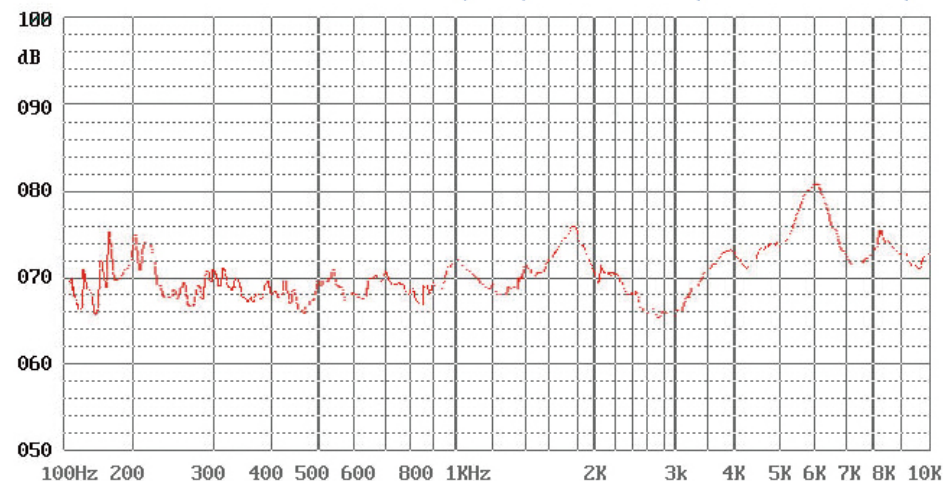

Picture:

Specification:

Rated Voltage	(Vp-p)	3
Max Input Voltage	(Vp-p)	25
*Rated Current	(mA)	≤3
Capacitance at 100Hz	(pF)	12000±30%
*Sound Output at 10cm	(dB)	≥65
Resonance Frequency	(KHz)	4.0±0.5
Operating Temperature	(°C)	-40~+105
Storage Temperature	(°C)	-40~+120
Weight	(g)	0.25
Housing Material		LCP
RoHS		Yes
MSL(Moisture Sensitivity Level)	5a(≤30°C/60% RH 24H F ₁₀₀ for life)	

*Value applying at rated voltage , 4.0KHz,1/2 duty , square wave

Test Basic State: Temp(20±2°C),Humidity(40~70%RH),Air pressure(860~1060hPa).

Frequency Response:

Dimensions (UNIT: mm)

Tolerance: ±0.5mm Except Specified

