

**Product Code:**

LPT2311AS-HS-09-4.0-19-R-1

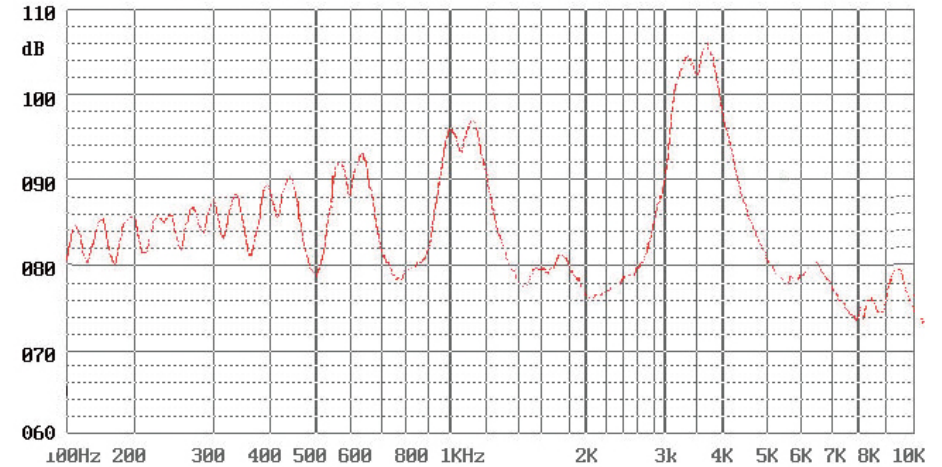

**Picture:**

**Specification:**

Rated Voltage	(Vp-p)	9
Max Input Voltage	(Vp-p)	30
*Rated Current	(mA)	≤9
Capacitance at 100Hz	(pF)	19000±30%
*Sound Output at 10cm	(dB)	≥100
Resonance Frequency	(KHz)	4.0±0.5
Operating Temperature	(°C)	-30~+85
Storage Temperature	(°C)	-40~+90
Weight	(g)	3.3
Housing Material		PPS
RoHS		Yes
MSL(Moisture Sensitivity Level)		5a(≤30°C/60% RH 24H F bor life)

\*Value applying at rated voltage , 4.0KHz, 1/2 duty , square wave

Test Basic State: Temp(20±2°C),Humidity(40~70%RH),Air pressure(860~1060hPa).

**Frequency Response:**

**Dimensions (UNIT: mm)**

Tolerance: ±0.5mm Except Specified

