

Product Code:

LET9045AS-03L-3.2-16-R-1

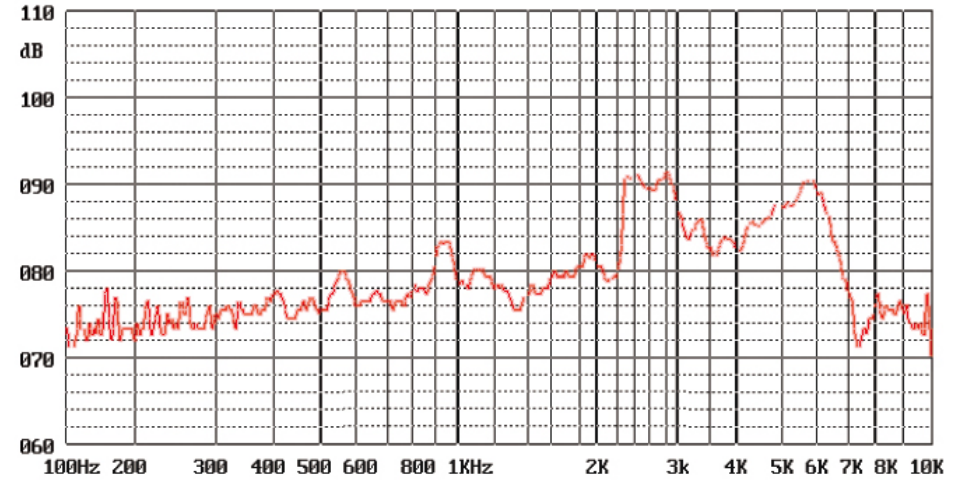

Picture:

Specification:

Rated Voltage	(Vo-p)	3
Operating Voltage	(Vo-p)	2~5
*Rated Current	(mA)	≤100
Coil Resistance	(Ω)	16±3
*Sound Output at 10cm	(dB)	≥90
Resonance Frequency	(Hz)	3200
Operating Temperature	(°C)	-40~+105
Storage Temperature	(°C)	-40~+120
Weight	(g)	0.5
Housing Material		LCP
RoHS		Yes
MSL(Moisture Sensitivity Level)		5a(≤30°C60% RH 24H F _{bor} life)

*Applying rated voltage and resonant frequency(1/2 duty square wave);

Test basic state: Temp(20±2°C), Humidity(40~70%RH), Air pressure(860~1060hPa).

Frequency Response:

Dimensions (Unit: mm)

Tolerance: ±0.5mm Except Specified

