

Interface module - VIP-2/PT/FLK14 - 2903788

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



VARIOFACE module, with push-in connections and flat-ribbon cable connector, for mounting on NS 35 rails, with pin strip and short and long locking latches for socket strips, 14-pos.

Key commercial data

package_quantity	1
GTIN	4046356796620

Technical data

Dimensions

Width	41.9 mm
Height	72.1 mm
Depth	56 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

General

Max. perm. operating voltage	60 V AC/DC
Max. perm. current (per branch)	1 A
Number of positions	14
Status display	No
Mounting position	any

Connection data for connection 1

Connection name	Field level
Connection method	Push-in connection
Stripping length	8 mm
Conductor cross section solid	0.14 mm ² ... 2.5 mm ²
Conductor cross section flexible	0.14 mm ² ... 2.5 mm ²
Conductor cross section AWG	26 ... 14

Connection data for connection 2

Connection name	Controller level
Connection method	IDC/FLK pin strip
Number of connections	1

Interface module - VIP-2/PT/FLK14 - 2903788

Technical data

Connection data for connection 2

Number of positions	14
Pitch	2.54 mm

Standards and Regulations

Connection in acc. with standard	CSA
Standards/regulations	IEC 60664
Standards/regulations	DIN EN 50178
Rated surge voltage	0.6 kV
Degree of pollution	2
Overvoltage category	II

Classifications

eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27250313
eCl@ss 5.1	27250313
eCl@ss 7.0	27141152
eCl@ss 8.0	27141152
eCl@ss 9.0	27141152

ETIM

ETIM 4.0	EC002780
ETIM 5.0	EC002780
ETIM 6.0	EC002780

UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421
UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	39121432

Approvals

CSA / UL Recognized / cUL Recognized / EAC / EAC / cULus Recognized /

Approval details

CSA ®	
Nominal voltage UN	125 V

Interface module - VIP-2/PT/FLK14 - 2903788

Approvals

Nominal current I _N	1 A
mm ² /AWG/kcmil	26-14

UL Recognized	
Nominal voltage U _N	125 V
Nominal current I _N	1 A
mm ² /AWG/kcmil	26-14

cUL Recognized	
Nominal voltage U _N	125 V
Nominal current I _N	1 A
mm ² /AWG/kcmil	26-14

EAC

ERC

cULus Recognized

Accessories

System cable

VIP-CAB-FLK14/0,14/0,5M - 2318389



VIP-CAB-FLK14/0,14/1,0M - 2318392



Interface module - VIP-2/PT/FLK14 - 2903788

Accessories

VIP-CAB-FLK14/0,14/1,5M - 2318402



VIP-CAB-FLK14/0,14/2,0M - 2318415



VIP-CAB-FLK14/0,14/3,0M - 2318428



VIP-CAB-FLK14/0,14/4,0M - 2318431



VIP-CAB-FLK14/0,14/6,0M - 2318444



VIP-CAB-FLK14-0,14/... - 2318457



Interface module - VIP-2/PT/FLK14 - 2903788

Accessories

FLK 14/EZ-DR/ 30/KONFEK - 2295729



FLK 14/EZ-DR/ 50/KONFEK - 2288901



FLK 14/EZ-DR/ 100/KONFEK - 2288914



FLK 14/EZ-DR/ 150/KONFEK - 2288927



FLK 14/EZ-DR/ 200/KONFEK - 2288930



Interface module - VIP-2/PT/FLK14 - 2903788

Accessories

FLK 14/EZ-DR/ 250/KONFEK - 2288943



FLK 14/EZ-DR/ 300/KONFEK - 2288956



FLK 14/EZ-DR/ 350/KONFEK - 2288969



FLK 14/EZ-DR/ 400/KONFEK - 2288972



FLK 14/EZ-DR/ 450/KONFEK - 2290847



FLK 14/EZ-DR/ 500/KONFEK - 2290834



Interface module - VIP-2/PT/FLK14 - 2903788

Accessories

FLK 14/EZ-DR/ 550/KONFEK - 2290850



FLK 14/EZ-DR/ 600/KONFEK - 2290863



FLK 14/EZ-DR/ 800/KONFEK - 2299563



FLK 14/EZ-DR/1000/KONFEK - 2299576



FLK EZ-DR.../.../... - 2295059



Interface module - VIP-2/PT/FLK14 - 2903788

Accessories

FLK 14/EZ-DR/ 50/KONFEK/S - 2296977



FLK 14/EZ-DR/ 100/KONFEK/S - 2296980



FLK 14/EZ-DR/ 200/KONFEK/S - 2297002



FLK 14/EZ-DR/ 300/KONFEK/S - 2299013



FLK 14/EZ-DR/ 400/KONFEK/S - 2299026



FLK 14/EZ-DR/ 600/KONFEK/S - 2299039



Interface module - VIP-2/PT/FLK14 - 2903788

Accessories

FLK 14/EZ-DR/ 800/KONFEK/S - 2299042



FLK 14/EZ-DR/1000/KONFEK/S - 2299055



FLK EZ-DR-S.../.../... - 2295046



FLK 14/EZ-DR/HF/ 50/KONFEK - 2305952



FLK 14/EZ-DR/HF/ 100/KONFEK - 2305965



Interface module - VIP-2/PT/FLK14 - 2903788

Accessories

FLK 14/EZ-DR/HF/ 150/KONFEK - 2305978



FLK 14/EZ-DR/HF/ 200/KONFEK - 2305981



FLK 14/EZ-DR/HF/ 250/KONFEK - 2305994



FLK 14/EZ-DR/HF/ 300/KONFEK - 2304759



FLK 14/EZ-DR/HF/ 400/KONFEK - 2304762



FLK 14/EZ-DR/HF/ 500/KONFEK - 2304717



Interface module - VIP-2/PT/FLK14 - 2903788

Accessories

FLK 14/EZ-DR/HF/ 600/KONFEK - 2306003



FLK 14/EZ-DR/HF/ 700/KONFEK - 2314011



FLK 14/EZ-DR/HF/ 800/KONFEK - 2314024



FLK 14/EZ-DR/HF/1000/KONFEK - 2314037



FLK 14-EZ-DR-HF/... - 2314040



Terminal marking

Interface module - VIP-2/PT/FLK14 - 2903788

Accessories

UC-TM 4 - 0818111



UC-TM 6 - 0818085



ZB 5,08:UNBEDRUCKT - 0809793



ZB 22:UNBEDRUCKT - 0811862



Printing system


BLUEMARK X1 - 5147777



Drawings

Interface module - VIP-2/PT/FLK14 - 2903788

Circuit diagram

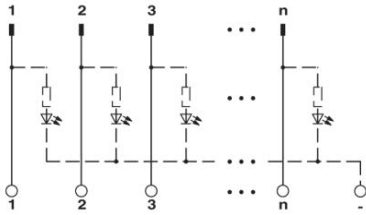

Phoenix Contact 2016 © - all rights reserved
<http://www.phoenixcontact.com>