
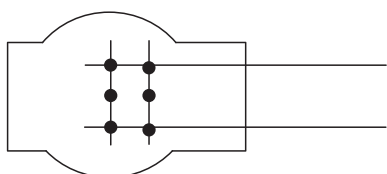
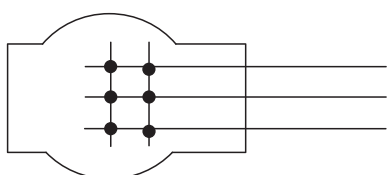


50pcs Wiring Connector Set 3 Wire Splice, Gel filled

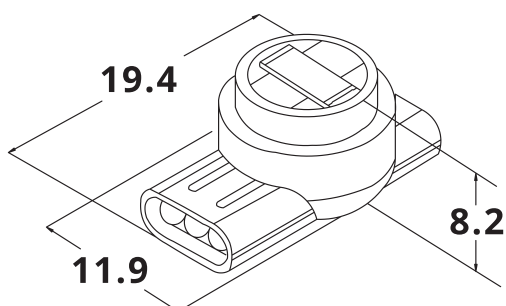

Butt Splicing 2 or 3 wires

Specification

- Insulation material:** PP
- Contact material:** Tinned Brass
- Color:** Red cap / Transparent base
- Wire range:** AWG 26 - 19
- Wire cross-section:** 0.13 - 0.65 mm²
- Conductor diameter:** 0,4 - 0,9 mm
- Voltage rating:** 300V max.
- Current rating:** 1.5A max
- Working temperature:** 0-65°C
- Working humidity:** 95% RH