
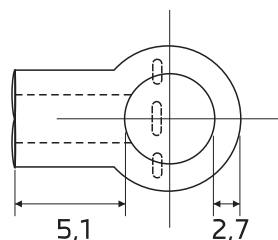
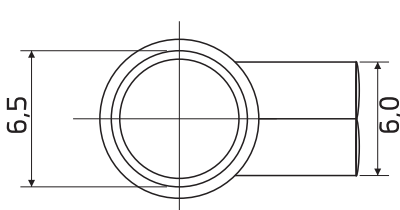
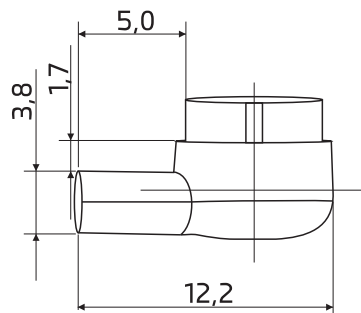
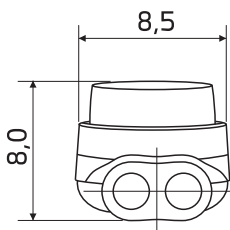


Data Sheet

Grease filled Lock Joint Wire Connector AWG 26 - 21, Self-stripping Tab 100pcs box set

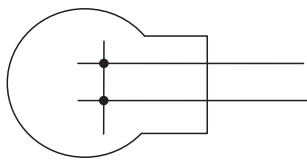

Specification

Insulation material: PC

Contact material: Tinned Brass

Color: Yellow cap / Transparent base

Wire range: AWG 26 - 21 (0.38-0.13mm²)

Insulation diameter: 1.52 mm (max.)

Conductor diameter: 0.4 ~ 0.7 mm

Voltage rating: < 50V/AC, 75V/DC

Current rating: 1.5A max.

Working temperature: 0-65°C

Working humidity: 95% RH

Package qty.: 100pcs