



 


Data Sheet

Wiring connector box set

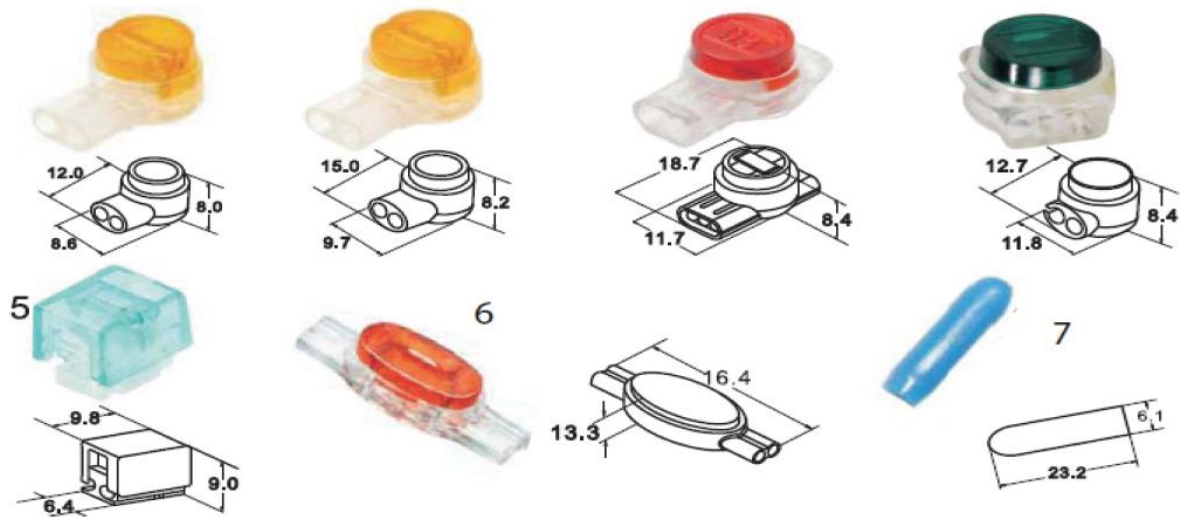

BN	max. wire dia.	conductor dia.	circuit
1564035	1.52 mm	0.4 - 0.7 mm	
1564036	1.52 mm	0.4 - 0.7 mm	
1563984	1.67 mm	0.4 - 0.9 mm	
1564037	1.67 mm	0.4 - 0.9 mm	
1564038	1.27 mm	0.4 - 0.7 mm	
1564039	2.0-3.3 mm	1.2 - 1.5 mm	
1564040	1.27 mm	0.32 - 0.7 mm	

Technical data

Contact pin: brass with tin plating