


Powered by Heavy Power Co Ltd

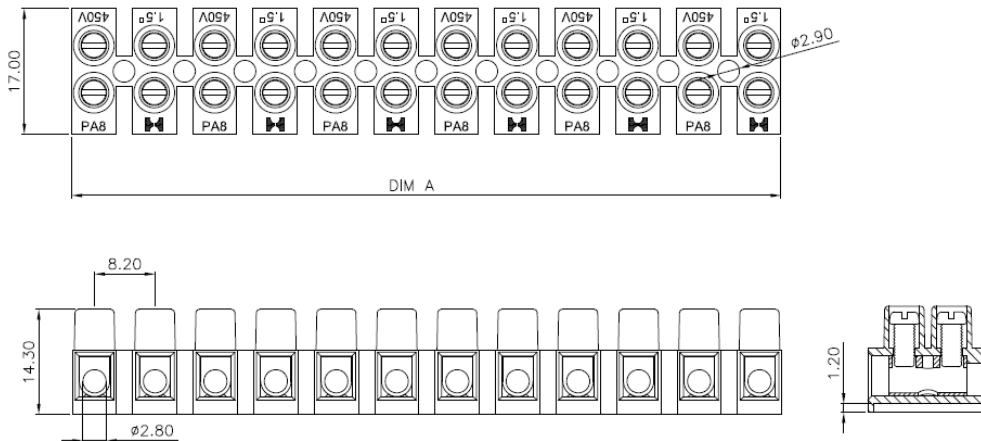

NO POSN	DIM A
2	14.2±0.3
3	22.4±0.3
4	30.6±0.5
5	38.8±0.5
6	47.0±0.5
7	55.2±0.7
8	63.4±0.7
9	71.6±0.7
10	79.8±0.7
11	88.0±1.0
12	96.2±1.0

ALL DIMENSION IN MM UNLESS OTHERWISE STATED : 0.=±0.2mm 00.=±0.4mm

Terminal Blocks

Model No.:	PA8
Part No.:	PA8H
Housing Material:	Polyamide (PA66), Nature flame-retardant to UL 94V-2
Voltage:	300V (UL)
Current:	20A (UL)
Working Temperature:	105°C
Insert:	Brass, Nickel-plated
Screws:	M2.6 x 5, Steel zinc-plated
Wire Range:	0.75 – 1.5mm ² , #22~#12 Sol/Str.
International Approvals:	UL