


Data Sheet

Easy-Link Lighting Connectors (500 PCS/PAK)



Drawing:

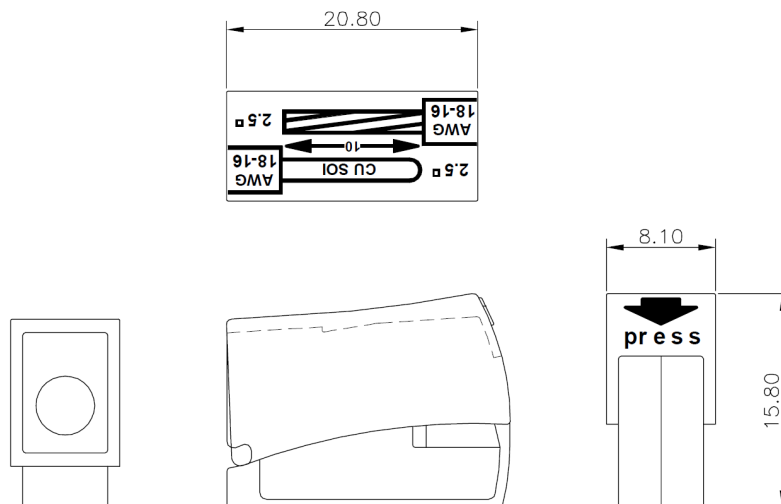

All dimension in mm unless otherwise stated: 0.=±0.2 mm, 00.=±0.4 mm

Technical data

Housing material: Polyamide 66 (PA66), flame-retardant to UL 94V-2

Current: 24 A (IEC)

Voltage: 450 V (IEC), 600 V (UL)

Stripping length: 9 ~ 11 mm

Operating temperature: T110 (IEC), 105 °C (UL)

Wire range: Installation side: 0.75 ~ 2.5 mm, Sol, #18-#16 AWG, Sol

Lighting side: 0.5 ~ 2.5 mm, Sol/Str, #18-#16 AWG, Sol/Str