


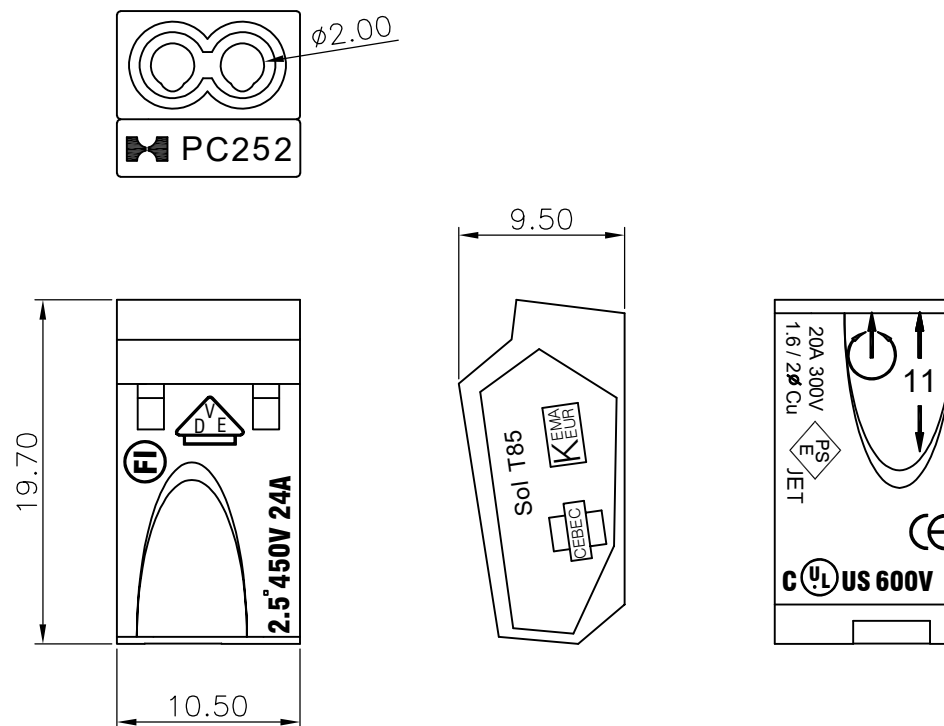

ALL DIMENSION IN MM UNLESS OTHERWISE STATED : 0.= ±0.2mm 00.= ±0.4mm

Housing Material : Polycarbonate (PC), flame-retardant to UL 94-V2

Current : 24A (IEC)

Voltage : 450V (IEC), 600V (UL)

Working Temp : T85 (IEC), 105° C (UL)

Stripping Length : 11mm (0.43inch)

Wire Range : 1.0 ~ 2.5mm², Sol (IEC)
#22-#12 AWG, Sol Cu (UL)

International Approvals

cULus, CE, VDE, FIMKO, KEMA, CEBEC, PSE, CQC



TITLE :

PUSH-IN WIRE CONNECTORS

Model No. PC252

Part No. PC252

Drawn By

Rev.

kuan
2021. 01. 04

A4