


## Membrane Keypad

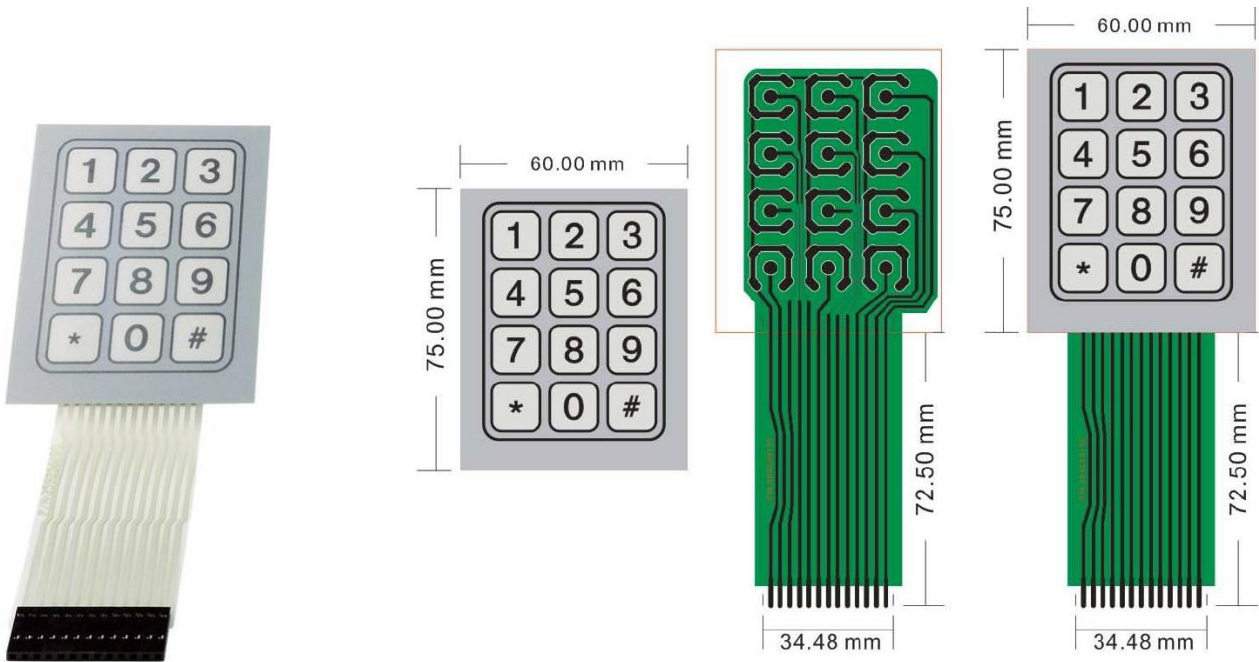

Gram Force .....	280g +/- 12g
Voltage Rating .....	30 V/DC max.
Current Rating .....	30mA max.
Contact Resistance .....	<50 ohm
Insulation Resistance .....	>100 M-ohm
Operating Temperature .....	-20°C ~ 60°C
Storage Temperature .....	-10°C ~ 60°C
Operating Humidity .....	0 ~ 90% RH
Storage Humidity .....	0 ~ 85% RH
Dimension tolerance .....	±0.3mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau ([www.conrad.com](http://www.conrad.com)).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.