



Data Sheet

Automotive wire FLRY-B, 0.75mm², 50m

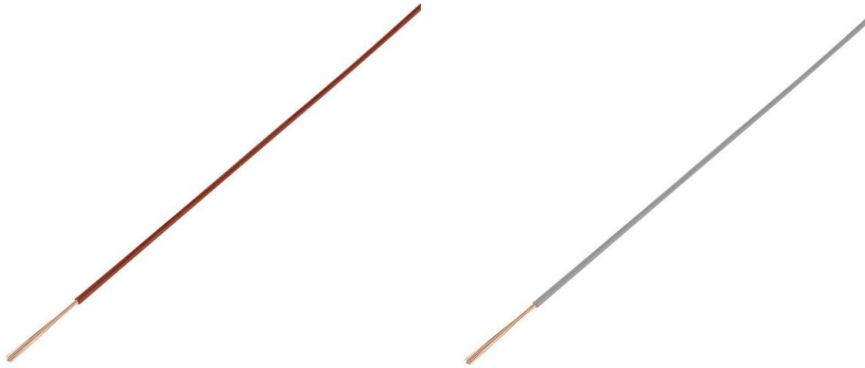

Item no.: 1564285	Blue	Item no.: 1568683	Green
Item no.: 1568681	Black	Item no.: 1568684	Grey
Item no.: 1565620	Red	Item no.: 1568685	Pink
Item no.: 1565621	Orange	Item no.: 1568686	Violet
Item no.: 1568682	Brown		
Item no.: 1564286	White		

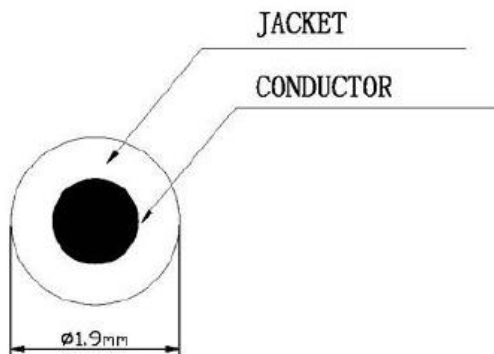

Data Sheet

Jacket, outer dimension.....	PVC 1.9mm
No. of conductors.....	24 x 0.21mm
Strand per conductor.....	0.75 mm ²
Length.....	50 meter
Conductor material	copper
Insulation material (with thickness).....	PVC 0.45mm
Core diameter.....	1.0 mm
Insulation resistance.....	Min 200M ohm x km
Maximum dielectric strength.....	1000V / AC
Temperature range.....	-40 to +105 °C
Rated voltage.....	< DC75 V / AC50 V
Resistance.....	24.7 mohm/M (20 °C)
Halogen-free.....	N
Lead-free.....	Y
Weight.....	9.0 kg/km