


Data Sheet

Multimeter Fuse F2



Dimensional Data

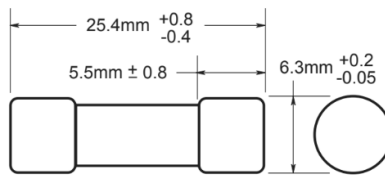

Limits for Pre-arcing Time

In	1.0 In.	1.6 In.	1.9 In.
	MIN	MIN	MAX
2A, 10A	1000 hours	30 min.	30 min.

Fast-Acting, High Braking Capacity Fuse

600 Volts AC

BS1362, UL Recognized

Electrical Ratings (Catalog Symbol and Amperes)

600 Volts

TDC600-2A

TDC600-10A

Rated Current	Rated Voltage (V)	Breaking Capacity	Power Dissipation (W)	Color	Approvals
2A 10A	600	200A,600V 10kA, 250V p.f. 0.7 - 0.8	1 Watt @ Rated Current	Blue	Asta, BSI

- 1/4" x 1" fast-acting, high breaking capacity fuse.
- Ceramic tube - end caps: silver-plated copper.
- Packaging: x 10, x 100, x 1000.
- Weight: 2.5g.

Data Sheet

Time-Current Characteristic Curves Average Melt (Full Size Curves Available)

