


Data Sheet

 
Female Connector with Plastic Cover Set, 260pcs/set, Black, Red, Blue

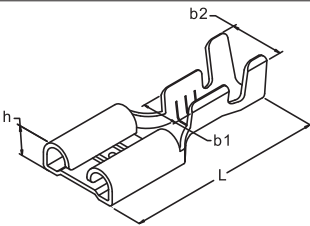

Blade receptacle

	2.8 x 0.8 0.14-0.3 30pcs		2.8 x 0.8 0.5-1.0 30pcs		4.8 x 0.8 0.5-1.0 20pcs		4.8 x 0.8 1.5-2.5 20pcs		6.3 x 0.8 0.5-1.0 15pcs		6.3 x 0.8 1.5-2.5 15pcs
		Fits Tab(mm)	Cross section(mm ²)	L(mm)	h(mm)	b1(mm)	b2(mm)				
		2.8 x 0.8	0.14-0.3	15.8	2.0	2.3	3.8				
			0.5-1.0	15.6	2.0	3.0	4.2				
		4.8 x 0.8	0.5-1.0	15.5	2.3	3.2	4.8				
			1.5-2.5	15.5	2.4	4.3	6.0				
		6.3 x 0.8	0.5-1.0	19.0	2.8	3.5	5.0				
			1.5-2.5	19.0	2.8	4.5	7.2				

PVC insulating sleeve

				2.8 x 0.8 Transparent BN 1571999 Blue BN 1566424 Black BN 1564997 Red BN 1564416 12pcs/color (total 48pcs)					4.8 x 0.8 Transparent BN 1564996 Blue BN 1566427 Black BN 1566428 Red BN 1571998 8pcs/color (total 32pcs)					6.3 x 0.8 Transparent BN 1566426 Blue BN 1571995 Black BN 1571996 Red BN 1572001 6pcs/color (total 24pcs)
					Receptacle(mm)	L(mm ²)	L1(mm)	d1(mm)	b2(mm)	w(mm)				
					2.8 x 0.8	23.0±2.0	15.5±1.5	4.0	Ø3.0	1.8				
					4.8 x 0.8	23.0±2.0	15.5±1.5	5.0	Ø3.0	2.3				
					6.3 x 0.8	25.0±2.0	18.0±2.0	8.0	Ø3.5	3.5				

Nylon insulating sleeve



BN 1572000

Transparent

2.8 x 0.8

12pcs



BN 1571997

Transparent

4.8 x 0.8

8pcs




BN 1566425

Transparent

6.3 x 0.8

6pcs

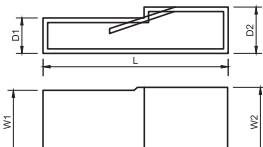

Receptacle(mm)	L(mm)	d1(mm)	d2(mm)	b2(mm)	w(mm)
2.8 x 0.8	20.2 ± 0.2	4.0 ± 0.1	4.4 ± 0.1	5.0 ± 0.1	5.4 ± 0.1
4.8 x 0.8	21.5 ± 0.2	4.0 ± 0.1	5.8 ± 0.1	7.0 ± 0.1	7.0 ± 0.1
6.3 x 0.8	25.0 ± 0.2	4.8 ± 0.1	6.3 ± 0.1	9.0 ± 0.1	9.4 ± 0.1